


DORMER

The Right Tool at the Right Time

The Dormer A002 'Drill-Boy' Is Back!*

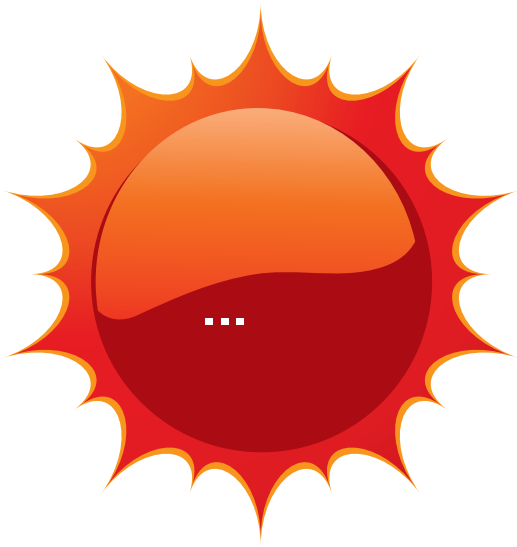

Drillboy, the revolutionary drill case incorporating a built in gauge that ensures correct tool selection, everytime!

Content:

- 43 x A002 HSS TiN Coated Jobber Drills
- Drill diameters 3.0 to 13.0 mm x 0.5 mm + 3.3, 4.2, 6.8 & 10.2 mm

Ø mm	drills number	Ø mm	drills number	Ø mm	drills number	Ø mm	drills number
3.00	3	5.50	2	8.50	1	11.50	1
3.30	3	6.00	2	9.00	1	12.00	1
3.50	3	6.50	2	9.50	1	12.50	1
4.00	3	6.80	2	10.00	1	13.00	1
4.20	2	7.00	2	10.20	1		
4.50	2	7.50	2	10.50	1		
5.00	2	8.00	2	11.00	1		

See over for official distributor order form

A002

DIN
338

4XD

HSS



118°



TiN



N



PS

A002	▪	1.1	1.2	1.3	1.4	3.1	3.2	7.1	7.2	8.1	8.2										
	•	1.5	1.6	2.1	2.2	2.3	3.3	3.4	4.1	4.2	4.3	5.1	5.2	5.3	6.1	6.2	6.3	6.4	7.3	7.4	
		8.3	9.1																		

A002 Features & Benefits



Marking

Visible with tool in-situ for easy identification.

Helix

Optimised for greater stiffness across diameter range.

Finish

Bright body improves performance on ductile materials.

Ground Tool

All surfaces ground for consistent precision.

Coating

Titanium nitride resists flank and crater wear and has low friction, promoting increased cutting speed possible.