


Deep groove ball bearings, single row, SKF Energy Efficient (E2) bearings



| Principal dimensions | | | Basic load ratings | | Fatigue load limit P_u | Speed ratings | | Mass | Designation |
|----------------------|----|----|--------------------|--------|-----------------------------|-----------------|----------------|------|---------------|
| d | D | B | dynamic | static | | Reference speed | Limiting speed | | |
| mm | | | kN | | kN | r/min | | kg | - |
| 40 | 90 | 23 | 41 | 24 | 1,02 | 19000 | 9900 | 0,63 | E2.6308-2Z/C3 |

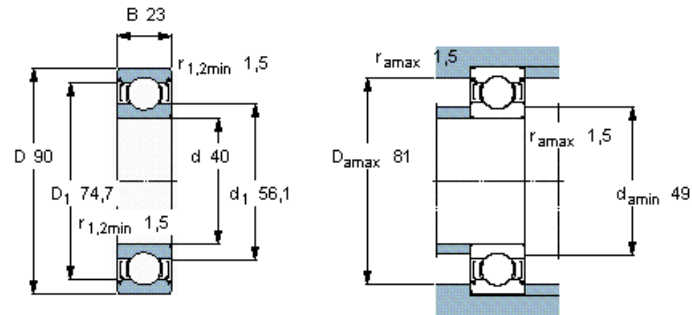

Calculation factors

k_r 0,03
 f_0 13