


Deep groove ball bearings, single row, unsealed



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	-
45	75	16	22,1	14,6	0,64	20000	12000	0,25	6009 *

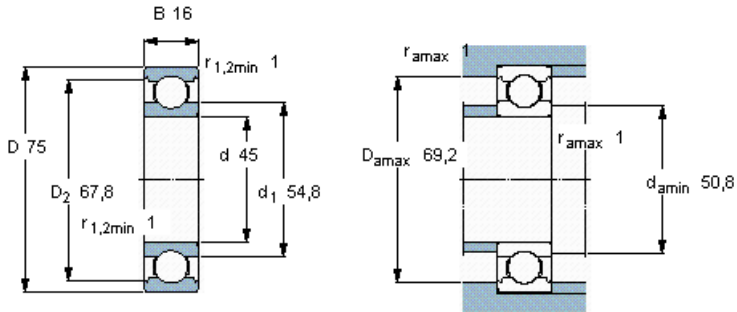

Calculation factors

k_f 0,025
 f_0 15