



# MASTER LEDcandle

MASTER LEDcandle D 3.5-25W B22 827 B39 CL

Delivering incandescent-like sparkling light effects, MASTER LEDcandle bulbs are ideal for general and decorative lighting in the hospitality industry, as well as in home environments. The dimmable MASTER LEDcandles drive further efficiencies, while helping to create the desired atmosphere. Mounted in full view in chandeliers, wall scones or modern luminaires, the clear or frosted glass bulbs fit all existing fixtures with an E14 and B15 socket. Drawing upon inputs from chandelier makers and designed to enhance the aesthetic appeal of the chandelier or luminaire, not only when lit but also when not, these lamps come in a classical slender shape with a unique, eye-catching lens design. They produce a beautiful sparkling warm light that delivers huge energy savings and minimizes maintenance cost. The flame-shaped candle lamp comes in a classical slender shape with a unique, eye-catching lens design that perfectly complements modern LED candles.

## Product data

### • General Characteristics

Cap-Base	B22
Bulb	B39
Bulb Finish	Clear
Rated Lifetime (hours)	20000 hr
Nominal Lifetime hours	20000 hr

### • Light Technical Characteristics

Color Code	827
Color Designation (text)	Warm White
Correlated Color Temperature	2700 K
Luminous Flux	250 Lm
Color rendering index	80
Luminous Efficacy Lamp	71.43 Lm/W
Color Temperature	2700 K [CCT 2700K]
Rated Luminous Flux	250 Lm
LLMF - end nominal lifetime	20000 %
Colour consistency	6 steps

### • Electrical Characteristics

Wattage	3.5 W
Wattage Technical	3.5 W
Voltage	220-240 V
Line Frequency	50-60 Hz
Power Factor	0.5 -
Lamp Current mA	29 mA
Dimmable	Yes
Wattage Equivalent	25 W

Rated Wattage	3.5 W
Starting Time	0.5 (max) s
Warm-up Time to 60% Light Outp	instant full light
Suitable for accent lighting	No

### • Temperature Characteristics

### • Environmental characteristics

Energy Efficiency Label (EEL)	A+
-------------------------------	----

### • Measuring Conditions

Switching cycle	50000X
-----------------	--------

### • Product Dimensions

Overall Length C	107 mm
Diameter D	39 mm

### • Product Data

Order code	929000273102
Full product code	929000273102
Full product name	MASTER LEDcandle D 3.5-25W B22 827 B39 CL
Order product name	MAS LEDcandle D 3.5-25W B22 827 B39 CL
Pieces per pack	1
Packing configuration	10
Packs per outerbox	10
Bar code on pack - EAN1	8718291743293




**PHILIPS**

# MASTER LEDcandle

Bar code on  
outerbox - EAN3 8718291743309  
Logistic code(s) -  
12NC 929000273102


Net weight per piece 0.068 kg

## Dimensional drawing

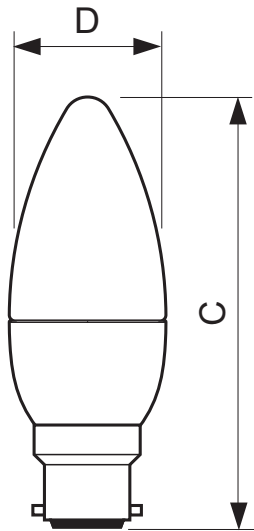


## MASTER LEDcandle D 3.5-25W B22 827 B39 CL

Product	C (Norm)	D (Norm)
LED D 3.5-25W B22 827 B39 CL	107	39

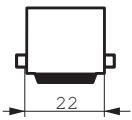

B22

## Photometric data

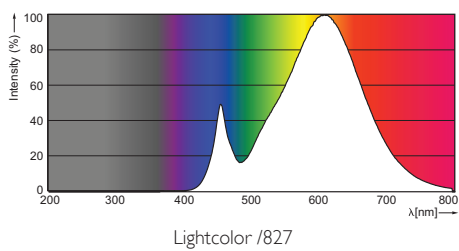

© 2014 Koninklijke Philips N.V. (Royal Philips)  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2014, June 28  
data subject to change