


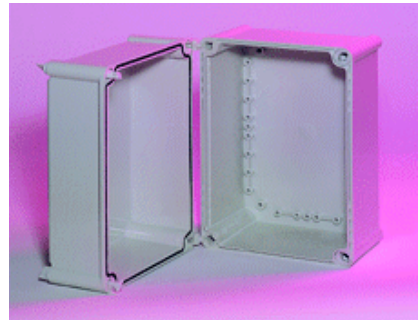

This is a sample photo.


**ORDER SYMBOL:** SC 2819 13 GII

**EL.number** **EAN:** 6418074036483  
Sweden:  
Denmark:  
Finland: 3422511

**INCLUDING:**  
Cabinet body, cover, hinges, quick-lock screws, and mounting screws.

**APPROVALS:**  
USA: NEMA 4, 4X, 12; UL 94-V0  
  
EURO: IP 65; UL 94-V0  
  
OTHERS: IEC 529, CE, EEI, SETI 163458-01

FIBOX SOLID SC II

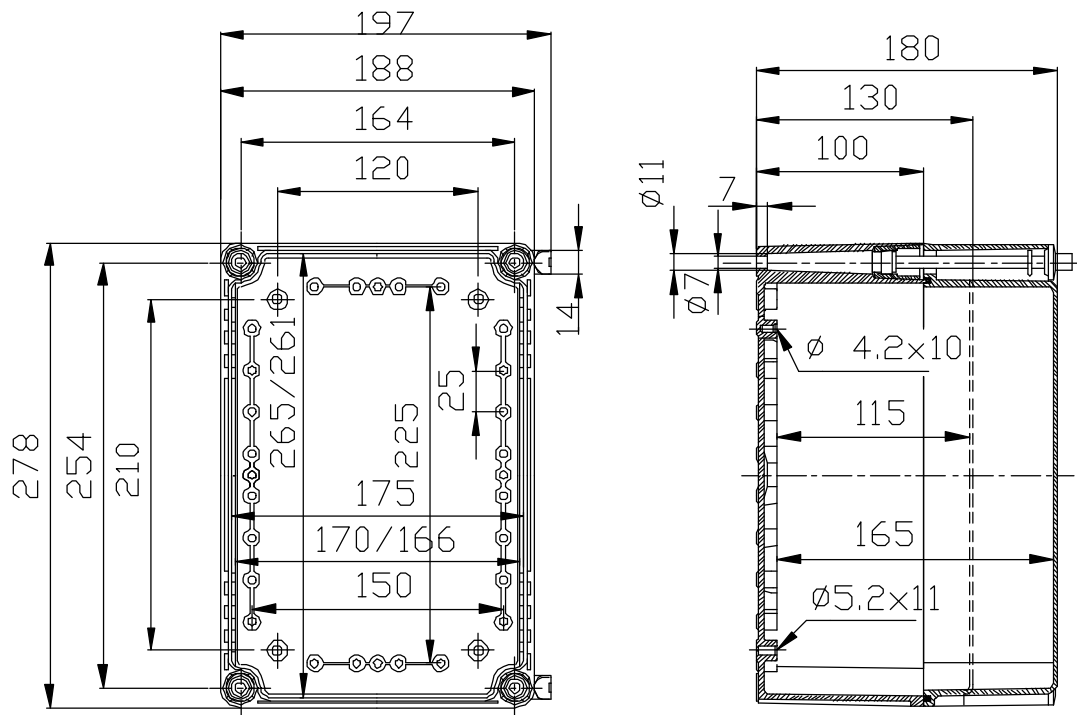

**TECHNICAL INFORMATION:**

Standard colour: RAL 7035  
Ingress protection: IP 65 (IEC 529)  
Flame resistance:

Temp.range in cont. use: Max. +80 °C  
Temp. range of material: - 40 °C - + 120 °C

**ACCESSORIES**

|                   |          |
|-------------------|----------|
| DIN-Rail          | EKV 12   |
| DIN-Rail          | EKV 14   |
| DIN-Rail          | EKV 22   |
| DIN-Rail          | EKV 24   |
| DIN-Rail          | EKV 32   |
| DIN-Rail          | EKV 34   |
| Corner plug       | MB 10523 |
| Fastening lug     | MB 10674 |
| Earth bar support | MB 26069 |
| Earth bar set     | MR 26059 |