

Portable Digital Microscope

Product Image



Model: AM 413MTFVW-A

Dino-Lite Pro AM413MTFVW-A
(USB) 10x-200x
UV on/off

AMITA STAND INCLUDED !!!!

TECHNICAL SPECIFICATIONS

- Resolution: 1.3M pixel
- Adjustable Magnification: 10x ~ 50x, 200x (Continuous magnification without changing lenses)
- Illumination: built-in 4 white LED (ON/OFF controlled by software)
- Illumination: built-in 4 UV LED (ON/OFF controlled by software)
- Frame rate: up to 30fps, 15fps at 1,3M
- **Excitation-UV LEDs, 400nm ; Emission Filter Cutoff Wavelength: 425nm**
- Interface: USB (PC) 2.0
- DinoCapture Software included
- Aluminum Alloy Housing

DIMENSIONS

- Size body :10cm (Length) *3.2cm (Diameter)
- weight: 95g

PRODUCT REQUIREMENTS

- Compatible with Windows 2000/XP, Vista and most MAC computers
- 256MB RAM
- CD ROM drive
- Available Hi-speed USB 2.0 port



GENERAL FEATURES

- Capture a photograph, video or time-lapsed video with a click of a button
- Save file format:jpg, bmp, avi
- Microtouch snapshot
- Accurate measurement & calibration capability

APPLICATIONS

- **Science / Engineering work / Study and Educational use / Dermatology / Detailed repair / Assembly & quality control / Electronic industry / Mechanical industry / Hobbies & collecting (coin, stamp, watch, jewelry, etc) / On line chatting / Antiques / Enforcement**

Demo Images

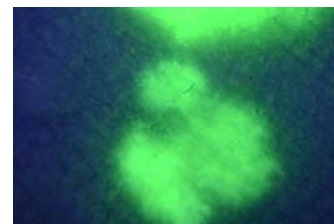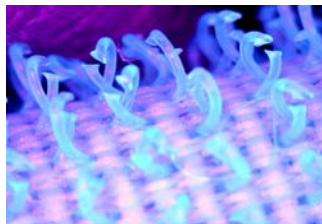

MANUFACTURED BY:



IMPORTED BY:



For more details visit the
website www.dinolite.it