
 


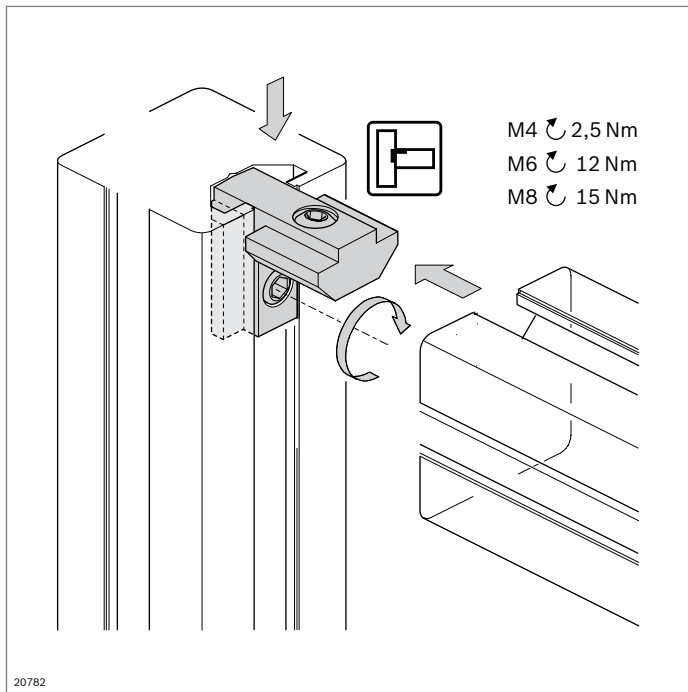


20782

Inner bracket



- For elegant, easy-to-assemble profile connections
- Especially suitable for constructing frames for doors, protective grilles, or partition walls
- The inner bracket, 6 mm slot, can also be used as an inner bracket R, 6 mm slot
- Profile finishing: not required

Technical data (p. 19-8)

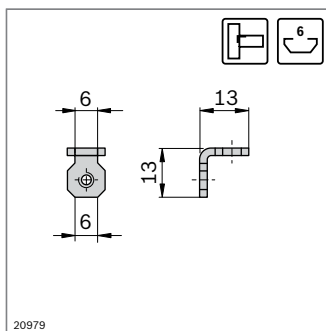


20979

FS1

DIN 915
M4x6

Inner bracket	Slot	ESD	No.	FS
	6 / 6		10	3 842 535 574 2xFS1

Material: sheet steel; galvanized
Fastening material: steel; galvanized
Scope of delivery: incl. fastening material (FS)

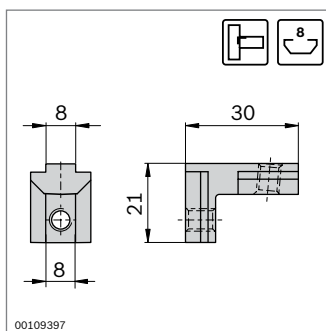

00109397

Slot


	F_{max}	M_{max}
8 / 8	2200 N	50 Nm

FS2

DIN 913
M6x8

Inner bracket	Slot	ESD	No.	FS
	8 / 8		10	3 842 535 578 2xFS2

Material: cast steel; galvanized
Fastening material: steel; galvanized
Scope of delivery: incl. fastening material (FS)

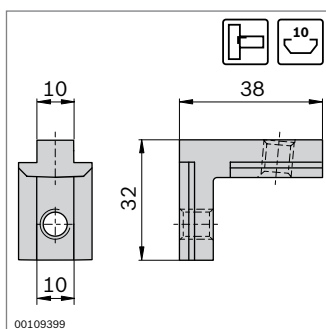

00109399

Slot

	F_{max}	M_{max}
10 / 10	2800 N	100 Nm

FS3

DIN 913
M8x12

Inner bracket	Slot	ESD	No.	FS
	10 / 10		10	3 842 535 572 2xFS3

Material: cast steel; galvanized
Fastening material: steel; galvanized
Scope of delivery: incl. fastening material (FS)