

# 95 61 190

## Wire Rope Cutter forged



- With two crimping dies for end caps on Bowden cable sheaths and end ferrules for traction cables
- Comfortable work thanks to handy, slim design and internal opening spring
- Bolted joint for precise blade guidance, re-adjustable
- High leverage for reduced effort
- Cutting-edge hardness approx. 64 HRC
- Chrome vanadium heavy-duty steel, forged, multi stage oil-hardened

Cuts all wire ropes without splaying, including those that are extremely strong


Article No.	95 61 190
EAN	4003773071983
Head	polished
Handles	plastic coated
Cutting capacity copper cable, multiple-stranded mm <sup>2</sup>	10
Cutting capacity copper cable, fine-stranded (diameter) Ø mm	6,00
Cutting capacities wire rope (diameter) Ø mm	5,0
Cutting capacities iron (diameter) Ø mm	4
Cutting capacities medium hard wire (diameter) Ø mm	4,0
Cutting capacity copper cable, multiple-stranded (diameter) Ø mm	7,0
Cutting capacities piano wire (diameter) Ø mm	2,5
AWG	7
Length mm	190
Net weight g	314



Crimping of the end ferrule onto the traction cable



Crimping of the end caps on the Bowden cable sheath

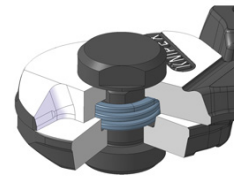

Internal opening spring

technical change and errors excepted

