



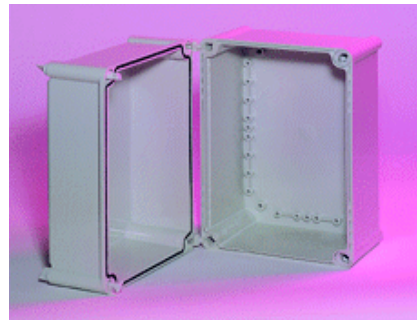

This is a sample photo.

ORDER SYMBOL: SC 2819 18 GII	
EL.number	EAN: 6418074036490
Sweden:	
Denmark:	
Finland: 3422516	
INCLUDING:	
Cabinet body, cover, hinges, quick-lock screws, and mounting screws.	
APPROVALS:	
USA: NEMA 4, 4X, 12; UL 94-V0	
EURO: IP 65; UL 94-V0	
OTHERS: IEC 529, CE, EEI, SETI 163458-01	

FIBOX SOLID SC II

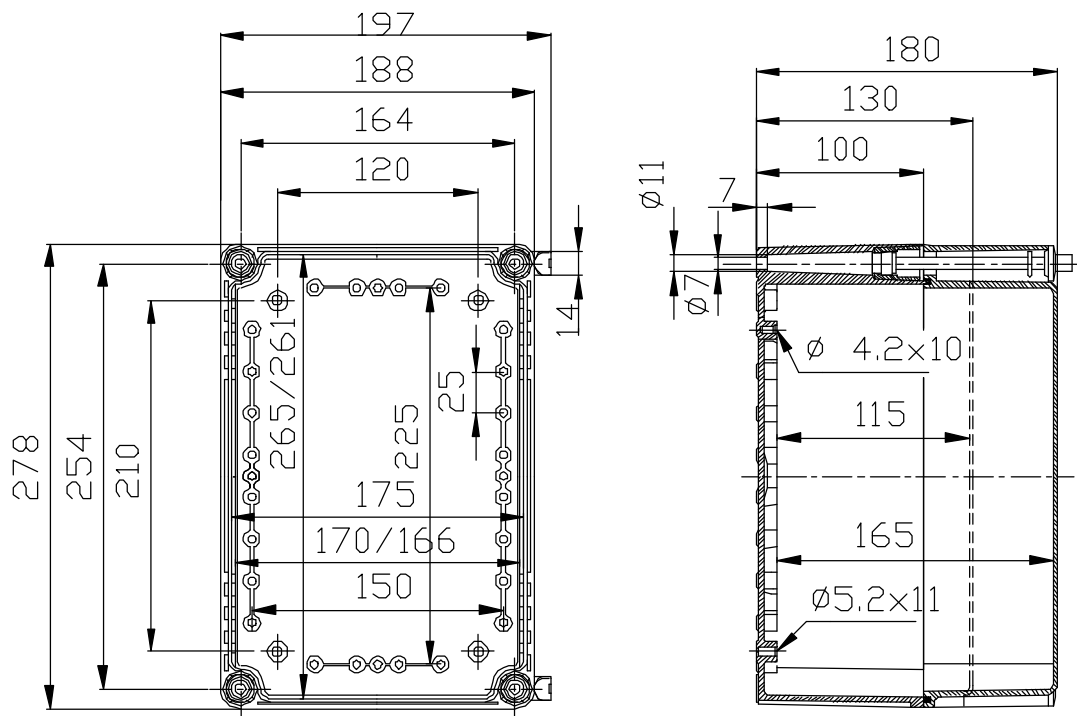

TECHNICAL INFORMATION:

Standard colour:	RAL 7035	Temp.range in cont. use:	Max. +80 °C
Ingress protection:	IP 65 (IEC 529)	Temp. range of material:	- 40 °C - + 120 °C
Flame resistance:			

ACCESSORIES

DIN-Rail	EKV 12	Earth bar set	MR 26059
DIN-Rail	EKV 14		
DIN-Rail	EKV 22		
DIN-Rail	EKV 24		
DIN-Rail	EKV 32		
DIN-Rail	EKV 34		
Corner plug	MB 10523		
Fastening lug	MB 10674		
Earth bar support	MB 26069		