


ACR Indust COG HT200C, Ceramic, 270 pF, 10%, 50 VDC, COG, Commercial, High Temperature, Lead Spacing = 5.08mm

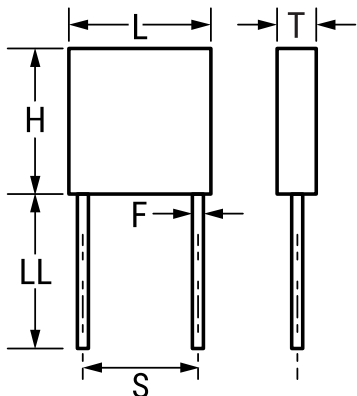

Dimensions

L	5.08mm MAX
H	5.08mm MAX
T	2.54mm MAX
S	5.08mm +/-0.38mm
LL	31.75mm MIN
F	0.508mm +/-0.051mm

Packaging Specifications

Packaging:	Bulk, Bag
Packaging Quantity:	1

General Information

Supplier:	KEMET
Series:	ACR Indust COG HT200C
Style:	Radial
Description:	Commercial, High Temperature
Features:	Commercial
RoHS:	No
Prop 65:	WARNING: Cancer and reproductive harm - www.p65warnings.ca.gov .
REACH:	SVHC (Pb – CAS 7439-92-1)
Termination:	Gold
Failure Rate:	N/A
Testing and Reliability:	Standard

Specifications

Capacitance:	270 pF
Capacitance Tolerance:	10%
Voltage DC:	50 VDC
Dielectric Withstanding Voltage:	125 VDC
Temperature Range:	-55/+200°C
Temperature Coefficient:	COG
Dissipation Factor:	0.15%
Insulation Resistance:	100 GOhms

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.