


# Deep groove ball bearings, single row, SKF Energy Efficient (E2) bearings



Principal dimensions			Basic load ratings		Fatigue load limit $P_u$	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
25	47	12	11,1	6,1	0,26	35000	18000	0,080	E2.6005-2Z/C3

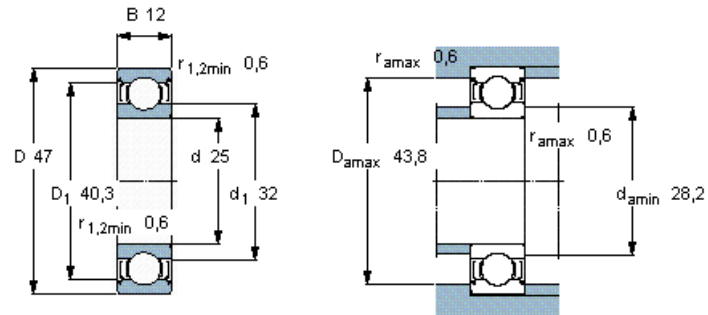

### Calculation factors

$k_r$  0,025  
 $f_0$  14