




Tapered roller bearings, single row

Principal dimensions			Basic load ratings		Speed ratings	Limiting speed	Designation
d	D	T	dynamic C	static C0	Reference speed		* SKF Explorer bearing
mm			kN		r/min		-
31,75	59,131	15,875	34,7	41,5	8500	12000	LM 67048/010/Q

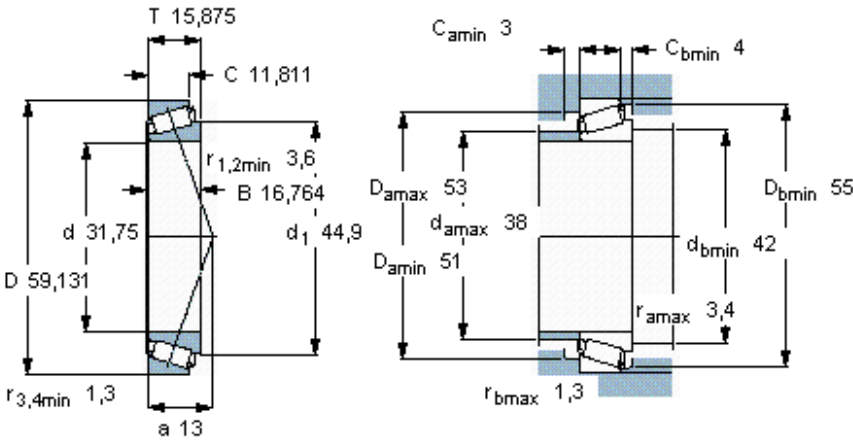

Calculation factors
e 0,4
Y 1,5
Y₀ 0,8