



Capsuleline

Capsuleline 35W GY6.35 12V CL 4000h 1CT

Single-ended low-voltage halogen capsule giving crisp white halogen light

Product data

• General Characteristics

Philips Code	13103
Cap-Base	GY6.35
Cap-Base Information	15
Bulb	T4 [T4: .434 inch / 11mm]
Bulb Finish	Clear
Burning Position	any [Any/Universal]
Nominal Lifetime	4000 hr
Rated Lifetime	4000 hr
Rated Lifetime (years)	4 an

• Light Technical Characteristics

Colour Rendering Index	100 Ra8
Colour Temperature	3000 K
Colour Temperature Technical	3000 K
Lamp Luminous Flux	600 Lm
Rated Luminous Flux	600 Lm
Lamp Luminous Efficiency	17 Lm/W
LLMF - end nominal lifetime	80 (min) %

• Electrical Characteristics

Rated Wattage	35.0 W
Lamp Wattage	35 W
Technical Lamp Power	35 W
Power Factor	1 -
Voltage	12 V
Lamp Current	2.95 A
Dimmable	yes
Starting Time	0.0 s

Warm-up Time to 60% Light Outp	instant full light
--------------------------------	--------------------

• Environmental Characteristics

Energy Efficiency Label (EEL)	C
Energy consumption kWh/1000h	37 kWh

• Measuring Conditions

Switching cycle	16000X
-----------------	--------

• Luminaire Design Requirements

Pinch Temperature	350 (max) C
Bulb Temperature	900 (max) C

• Product Dimensions

Overall Length C	44 (max) mm
Diameter D	12 (max) mm
Light Center Length L	30 mm

• Product Data

Order code	402189 50
Full product code	871150040218950
Full product name	Capsuleline 35W GY6.35 12V CL 4000h 1CT
Order product name	Caps 35W GY6.35 12V CL 4000h 1CT/10X10F
Pieces per pack	1
Packing configuration	10X10F
Packs per outerbox	100


PHILIPS

Capsuleline

Bar code on pack - EAN1 8711500402189
Bar code on intermediate packing - EAN2 8711500416957
Bar code on outerbox - EAN3 8711500425775


Logistic code(s) - 924040317101
12NC
ILCOS code HSG/C/UB-35-12-GY6.35
Net weight per piece 2.300 gr

Dimensional drawing

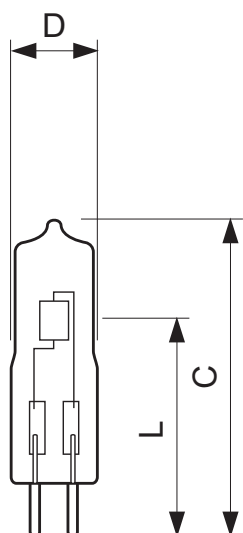

Capsuleline 35W GY6.35 12V CL 4000h 1CT

Product	C (Max)	D (Max)	L (Norm)
CAP SU 13103 35W GY6.35 12V CL	44	12	30

 

GY6.35



© 2014 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, November 5
data subject to change