


Datasheet

SPDT Toggle Switch On-Off-On


RS Stock number 401-674

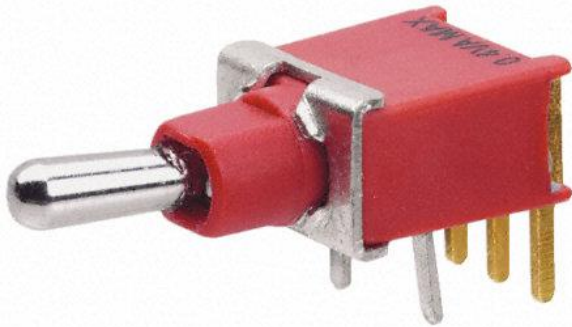


Specifications:

Mechanical Life:	50,000 make-and-break cycles
Contact Resistance:	20m Ω max. initial @ 2-4VDC, 100mA for both silver and gold plated contacts
Insulation Resistance:	1,000M Ω min.
Dielectric Strength:	1,000V RMS @ sea level
Operating Temperature:	-30°C to 85°C
Case & Bushing:	Glass filled nylon 6/6, retardant, heat stabilized (UL94V-0)
Actuator:	Brass, chrome plated. Internal O-ring seal. Standard for all actuators
Switch Support:	Brass, tin plated
Terminals/Contact:	Silver or gold plated copper.
RoHS:	2002/95/EC
Rating:	R: 0.4VA max. @ 20V max. (AC or DC) Q: 1A @ 250VAC 3A @ 120VAC or 28VDC

**Dimensions – inch
mm**

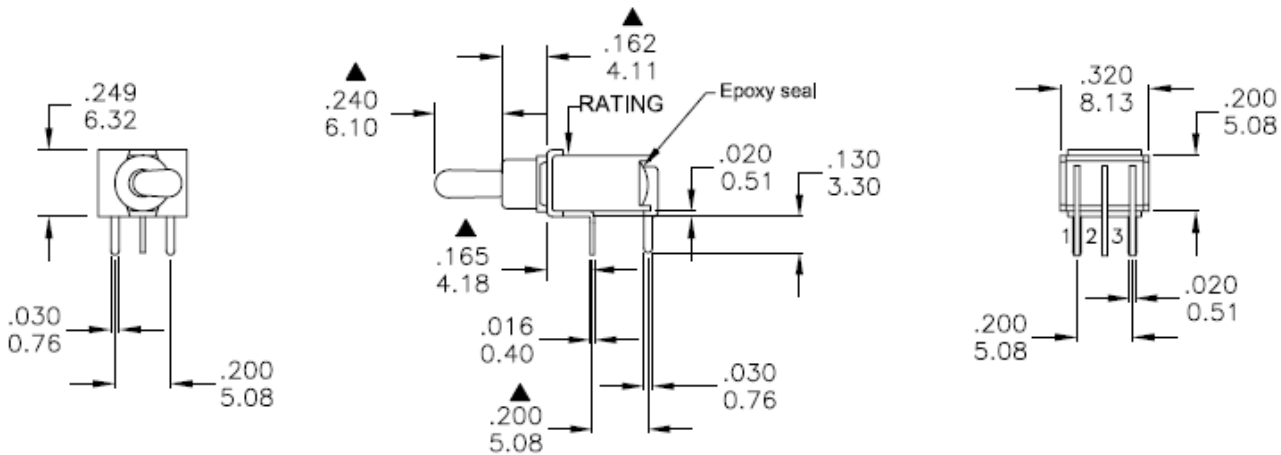

P.C. MOUNTING

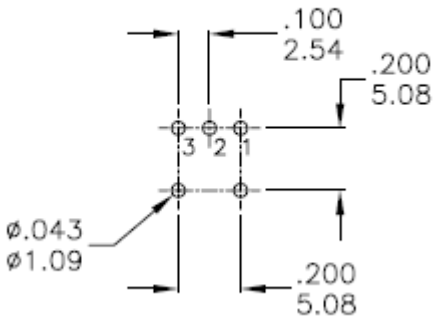

Model No.	POS.1	POS.2	POS.3
2AS3	ON	OFF	ON
Term. Comm.	2-3	OPEN	2-1
SCHEMATIC			

SWITCH FUNCTION