



Datasheet

ENGLISH

Stock No: 831-9046

RS Pro PG7 Nickel Plated Brass Cable Gland With Locknut



Specifications:

Material: Brass Nickel Plated

Sealing: Neoprene

Claw: PA6

Temperature:

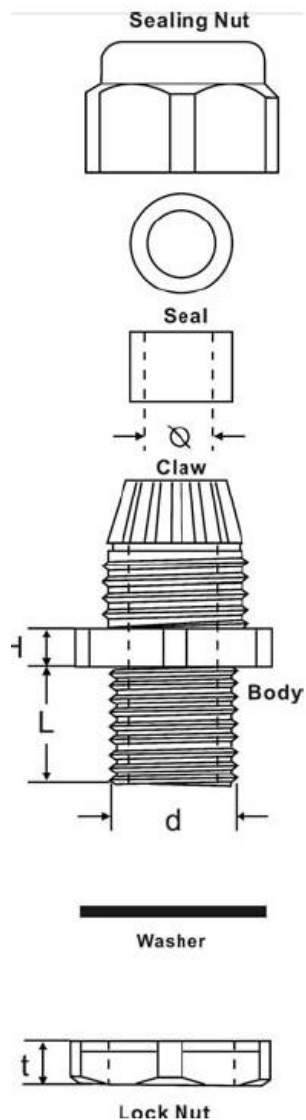
Normal: -40 °C ~ +100 °C.

Short Time: +120 °C

Standard: RoHS, CE, IP68

Features: Brass glands are frequently used in the shipping and the offshore industry.

RoHS CE

Dimensions:


| RS Article No. | SIZE | Cable Range (Φ) (MM) | d (MM) | H (MM) | L (MM) | t (MM) |
|----------------|---------|-------------------------|-----------|-----------|-----------|-----------|
| 831-9012 | M12×1.5 | 3—6.5 | 12 | 14 | 6 | 2.8 |
| 831-9021 | M16×1.5 | 5—10 | 16 | 20 | 6 | 2.2 |
| 831-9024 | M20×1.5 | 8—14 | 20 | 24 | 8 | 3.0 |
| 831-9028 | M25×1.5 | 9—16 | 25 | 27 | 7.5 | 3.0 |
| 831-9037 | M32×1.5 | 15—22 | 32 | 35 | 8.5 | 3.5 |
| 831-9030 | M40×1.5 | 22—32 | 40 | 50 | 12 | 4.5 |
| 831-9034 | M50×1.5 | 31—38 | 50 | 57 | 12 | 5.0 |
| 831-9043 | M63×1.5 | 37—44 | 63 | 65 | 12 | 5.5 |
| 831-9046 | PG7 | 3—6.5 | 12.5 | 14 | 6 | 2.8 |
| 831-9040 | PG9 | 4—8 | 15.2 | 18 | 6.5 | 2.5 |
| 831-9059 | PG11 | 5—10 | 18.6 | 20 | 7 | 3.0 |
| 831-9052 | PG13.5 | 6—12 | 20.4 | 22 | 7.5 | 3.0 |
| 831-9056 | PG16 | 8—14 | 22.5 | 24 | 7 | 3.0 |
| 831-9065 | PG21 | 13—18 | 28.3 | 30 | 8 | 3.5 |
| 831-9068 | PG29 | 18—25 | 37.0 | 40 | 9.5 | 4.0 |
| 831-9062 | PG36 | 22—32 | 47.0 | 50 | 12 | 4.5 |