



ENGLISH

Datasheet

RS Pro M25 Black Nylon Cable Gland With Locknut, 13 → 18mm Cable Dia Range, IP68

Stock No: 669-4676




Colour	Black
IP Rating	IP68
Locknut Included	Yes
Material	Nylon 66
Maximum Cable Diameter	18mm
Maximum Operating Temperature	+85°C
Minimum Cable Diameter	13mm
Minimum Operating Temperature	-60°C
Thread Size	M25



ENGLISH

Datasheet

LOCK NUT

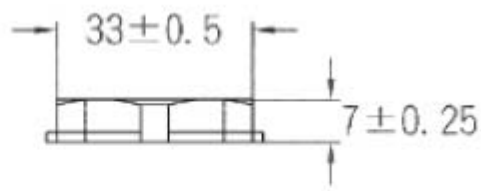

WASHER

External thread
M25x1.5

18.6 ± 0.35

BODY


15.2 ± 0.35

CLAW

29.4 ± 0.5

18.4 ± 0.5

SEALS

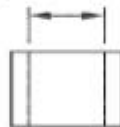

NUT

