


VIP-3/SC/FLK50

Order No.: 2315081

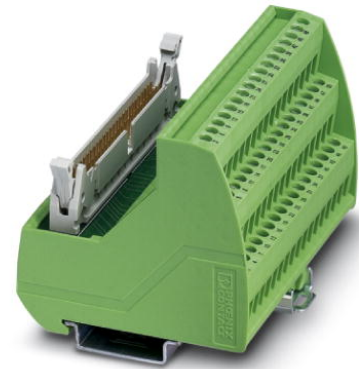

<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=2315081>


VARIOFACE module, with screw connection and flat-ribbon cable plug connector, for mounting on NS 32 or NS 35/7.5, with pin strip and short and long locking latches for socket strips, 50-pos.



Commercial data	
EAN	4046356312899
Pack	1 pcs.
Customs tariff	85369010
Weight/Piece	0.24 KG
Catalog page information	Page 279 (IF-2009)

Product notes

WEEE/RoHS-compliant since:
09/02/2008



<http://www.download.phoenixcontact.com>
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

Technical data

General data	
Nominal voltage U_N	60 V AC/DC
Max. current carrying capacity per branch	1 A
Number of positions	50
Width	92.7 mm

Height	60.8 mm
Depth	68.8 mm
Ambient temperature (operation)	-20 °C ... 50 °C
Ambient temperature (storage/transport)	-20 °C ... 70 °C
Mounting position	Any
Standards/regulations	IEC 60664
	DIN EN 50178
	IEC 62103
Pollution degree	2
Surge voltage category	II

Connection data

Connection 1	PCB connection
Connection in acc. with standard	IEC / EN
Type of connection	Screw connection
Conductor cross section solid min.	0.2 mm ²
Conductor cross section solid max.	4 mm ²
Conductor cross section stranded min.	0.2 mm ²
Conductor cross section stranded max.	2.5 mm ²
Conductor cross section AWG/kcmil min.	24
Conductor cross section AWG/kcmil max	12
Stripping length	8 mm
Screw thread	M 3

Certificates / Approvals



Certification CUL, UL

CUL

Nominal voltage U_N	125 V
Nominal current I_N	1 A
AWG/kcmil	30-12

UL

Nominal voltage U_N	125 V
Nominal current I_N	1 A
AWG/kcmil	30-12

Accessories

Item	Designation	Description
Cable/conductor		
2314257	CABLE-FLK50-0,14/HF/...	Assembled halogen-free round cable, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels. Halogen-free refers exclusively to the 50-pos. cable.Length of cable: Variable
2314134	CABLE-FLK50/0,14/HF/ 0,5M	Assembled halogen-free round cable, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels. Halogen-free refers exclusively to the 50-pos. cable.Length of cable: 0.55 yd
2314147	CABLE-FLK50/0,14/HF/ 1,0M	Assembled halogen-free round cable, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels. Halogen-free refers exclusively to the 50-pos. cable.Length of cable: 1 m
2314150	CABLE-FLK50/0,14/HF/ 1,5M	Assembled halogen-free round cable, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels. Halogen-free refers exclusively to the 50-pos. cable.Length of cable: 1.64 yd
2314163	CABLE-FLK50/0,14/HF/ 2,0M	Assembled halogen-free round cable, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels. Halogen-free refers exclusively to the 50-pos. cable.Length of cable: 2.19 yd
2314176	CABLE-FLK50/0,14/HF/ 2,5M	Assembled halogen-free round cable, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels. Halogen-free refers exclusively to the 50-pos. cable.Length of cable: 2.73 yd
2314202	CABLE-FLK50/0,14/HF/ 5,0M	Assembled halogen-free round cable, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels. Halogen-free refers exclusively to the 50-pos. cable.Length of cable: 5 m
2314215	CABLE-FLK50/0,14/HF/ 6,0M	Assembled halogen-free round cable, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels. Halogen-free refers exclusively to the 50-pos. cable.Length of cable: 6 m
2314228	CABLE-FLK50/0,14/HF/ 7,0M	Assembled halogen-free round cable, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels. Halogen-free refers exclusively to the 50-pos. cable.Length of cable: 7 m
2314231	CABLE-FLK50/0,14/HF/ 8,0M	Assembled halogen-free round cable, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels. Halogen-free refers exclusively to the 50-pos. cable.Length of cable: 8 m
2289065	FLK 50/EZ-DR/ 50/KONFEK	Round cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 0.5 m
2299097	FLK 50/EZ-DR/ 50/KONFEK/S	Round shielded cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 0.5 m

2289078	FLK 50/EZ-DR/ 100/KONFEK	Round cable sets, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 1 m
2299107	FLK 50/EZ-DR/ 100/KONFEK/S	Round shielded cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 1 m
2289081	FLK 50/EZ-DR/ 150/KONFEK	Round cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 1.5 m
2299110	FLK 50/EZ-DR/ 150/KONFEK/S	Round shielded cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 1.5 m
2289094	FLK 50/EZ-DR/ 200/KONFEK	Round cable sets, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 2 m
2299123	FLK 50/EZ-DR/ 200/KONFEK/S	Round shielded cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 2 m
2289104	FLK 50/EZ-DR/ 250/KONFEK	Round cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 2.5 m
2289117	FLK 50/EZ-DR/ 300/KONFEK	Round cable sets, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 3 m
2299136	FLK 50/EZ-DR/ 300/KONFEK/S	Round shielded cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 3 m
2289120	FLK 50/EZ-DR/ 350/KONFEK	Round cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 3.5 m
2289133	FLK 50/EZ-DR/ 400/KONFEK	Round cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 4 m
2299149	FLK 50/EZ-DR/ 400/KONFEK/S	Round shielded cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 4 m
2289573	FLK 50/EZ-DR/ 450/KONFEK	Round cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 4,5 m
2289586	FLK 50/EZ-DR/ 500/KONFEK	Round cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 5 m
2289599	FLK 50/EZ-DR/ 550/KONFEK	Round cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 5,5 m
2289609	FLK 50/EZ-DR/ 600/KONFEK	Round cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 6 m
2299152	FLK 50/EZ-DR/ 600/KONFEK/S	Round shielded cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 6 m
2289612	FLK 50/EZ-DR/ 650/KONFEK	Round cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 6.5 m
2289625	FLK 50/EZ-DR/ 700/KONFEK	Round cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 7 m
2289638	FLK 50/EZ-DR/ 750/KONFEK	Round cable set, with two 50-pos. female connectors (1:1 connection), for connecting 32 channels, cable length: 7.5 m
2289641	FLK 50/EZ-DR/ 800/KONFEK	Round cable sets, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 8 m
2299165	FLK 50/EZ-DR/ 800/KONFEK/S	Round shielded cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 8 m

2289654	FLK 50/EZ-DR/ 850/KONFEK	Round cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 8.5 m
2289667	FLK 50/EZ-DR/ 900/KONFEK	Round cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 9 m
2289670	FLK 50/EZ-DR/ 950/KONFEK	Round cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 9.5 m
2289683	FLK 50/EZ-DR/1000/KONFEK	Round cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 10 m
2299178	FLK 50/EZ-DR/1000/KONFEK/S	Round shielded cable set, with two 50-pos. socket strips (1:1 connection), for connecting 32 channels, cable length: 10 m
2295046	FLK EZ-DR-S.../.../...	Round cable, with preassembly, shielded, variable cable length
2295059	FLK EZ-DR.../.../...	Round cable, with preassembly, not shielded, variable cable length
2318936	VIP-CAB-FLK50-0,14/...	Assembled round cable with two molded 50-pos. socket strips (1:1 connection). The cable has a 90° punched on connector and a 180° punched on connector, cable length: Variable
2318868	VIP-CAB-FLK50/0,14/0,5M	Assembled round cable with two molded 50-pos. socket strips (1:1 connection). The cable has a 90° punched on connector and a 180° punched on connector, cable length: 0.5 m
2318871	VIP-CAB-FLK50/0,14/1,0M	Assembled round cable with two molded 50-pos. socket strips (1:1 connection). The cable has a 90° punched on connector and a 180° punched on connector, cable length: 1 m
2318884	VIP-CAB-FLK50/0,14/1,5M	Assembled round cable with two molded 50-pos. socket strips (1:1 connection). The cable has a 90° punched on connector and a 180° punched on connector, cable length: 1.5 m
2318897	VIP-CAB-FLK50/0,14/2,0M	Assembled round cable with two molded 50-pos. socket strips (1:1 connection). The cable has a 90° punched on connector and a 180° punched on connector, cable length: 2 m
2318907	VIP-CAB-FLK50/0,14/3,0M	Assembled round cable with two molded 50-pos. socket strips (1:1 connection). The cable has a 90° punched on connector and a 180° punched on connector, cable length: 3 m
2318910	VIP-CAB-FLK50/0,14/4,0M	Assembled round cable with two molded 50-pos. socket strips (1:1 connection). The cable has a 90° punched on connector and a 180° punched on connector, cable length: 4 m
2318923	VIP-CAB-FLK50/0,14/6,0M	Assembled round cable with two molded 50-pos. socket strips (1:1 connection). The cable has a 90° punched on connector and a 180° punched on connector, cable length: 6 m

General

5147777	BLUEMARK X1	Printers with UV technology for printing plastic labels in UniCard format.
---------	-------------	--


Marking

0818111	UC-TM 4	UniCard sheets, for labeling terminal blocks using a Zack marker strip groove, 120-section, can be labeled with BLUEMARK X1 and CMS-P1-PLOTTER, color: White
---------	---------	--

0818085	UC-TM 6	UniCard sheets, for labeling terminal blocks using Zack marker strip groove,80-section, labeling with BLUEMARK X1 and CMS-P1-PLOTTER, color: White
0811862	ZB 22:UNBEDRUCKT	Zack marker strip, unprinted: 4-section, for individual labeling with M-PEN, ZB-T or CMS system, sufficient for 100 terminal blocks, for a terminal width of 22 mm, color: White
0809793	ZB 5,08:UNBEDRUCKT	Zack strip, unprinted: 10-section, for individual labeling with M-PEN, ZB-T or CMS system, sufficient for 100 terminal blocks per pack

Drawings

Circuit diagram

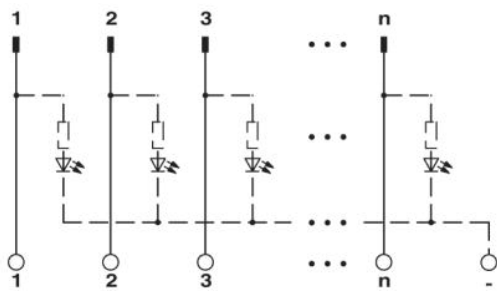

Address

PHOENIX CONTACT Ltd
Halesfield 13
Telford Shropshire TF7 4PG,GB
Phone 01952 681 700
Fax 01952 681 799
<http://www.phoenixcontact.co.uk>



© 2009 Phoenix Contact
Technical modifications reserved;