



SXL4



TYPICAL APPLICATIONS

Coffee machines, washing machines

FUNCTIONS

- SPST, momentary or not
- SPST, illuminated or not
- DPST, momentary or not
- DPST, illuminated or not

CYCLE No.

50.000

CUT OUT

19x13 mm

AMBIENT TEMPERATURE

125 °C

GWT

850 °C

GWT NO FLAME (<2sec)

750 °C

S

X

L


4

?


?

DRAWING


1 FLAT

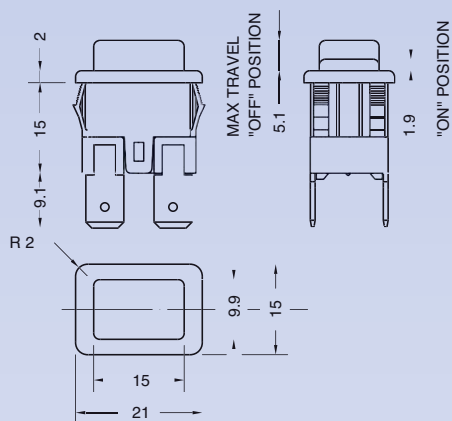

2 BOWL

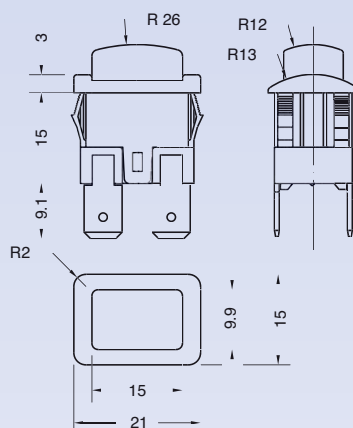

3 CUSTOMIZABLE

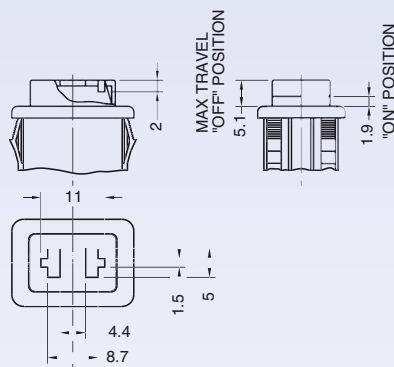

TERMINAL

1 Drawing 1 - 2 - 3 Vertical terminal 6.3x0.8



A Drawing 1 Horizontal terminal 6.3x0.8



2 Drawing 1 - 2 - 3 Vertical terminal 4.8x0.8




B Drawing 1 - 3 Horizontal terminal 4.8x0.8





4 Drawing 1 - 2 Vertical PCB terminal



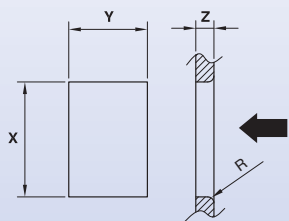

Z	Y	X
0,5-1,2	12,9	$+0,1$ 0
1,2-2,0	12,9	$+0,1$ 0
2,0-3,0	12,9	$+0,1$ 0

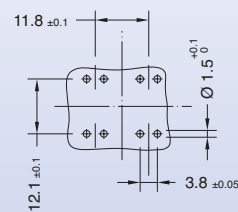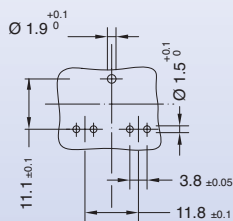

DRAWING	TERMINAL	FUNCTION	RATING	BODY COLOUR	BUTTON COLOUR	MARKING COLOUR	MARKING
S	X	L	4				
							0 0 0 W


?	?	?	?	?	?	?	0	0	0	W
---	---	---	---	---	---	---	---	---	---	---

FUNCTION

1



 2




4




6 No drawing 3



 7



8 No drawing 3

 

RATING

H

16 (4) A / 250 VAC
10 (6) A / 250 VAC - 5E4
T125/55 °C
EN 61058

16 A - 125 / 250 VAC
3/4 HP - 125 / 250 VAC
T100 °C
UL 1054

9

12 (8) A / 250 VAC - 5E4
T85/55 °C
EN 61058

BODY COLOUR

1

black

2

white

X

custom

BUTTON COLOUR

Drawing 1 - 3

1

black

2

white

Drawing 1 - 2

M

white

N

black

R

red

ILLUMINATED ✱

G

red

H

orange

E

green

L

white

F

blue

X

custom

MARKING COLOUR

0

none

1

black

2

white

X

custom

MARKING

0



1



R



X

