


# SU SERIES

### Technical data

Protection class IP40

Operating temperature -10°C ~ +60°C

## SU ROUND SHAPE PLASTIC CASE

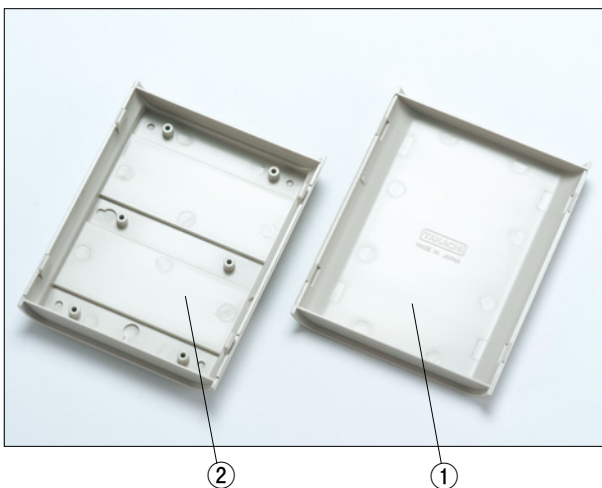

### FEATURE

- Round shape plastic case.
- Suitable for wall-mount.
- Snap on / off the cover. No screws are necessary.


### Components

Ref. #	Part name	Pcs	Material	Color
1	Top cover	1	ABS (UL94HB)	Light gray · Dark gray · White
2	Bottom cover	1	ABS (UL94HB)	Light gray · Dark gray · White


• CAD data is downloadable from our website.

SU dimensions

SU-140

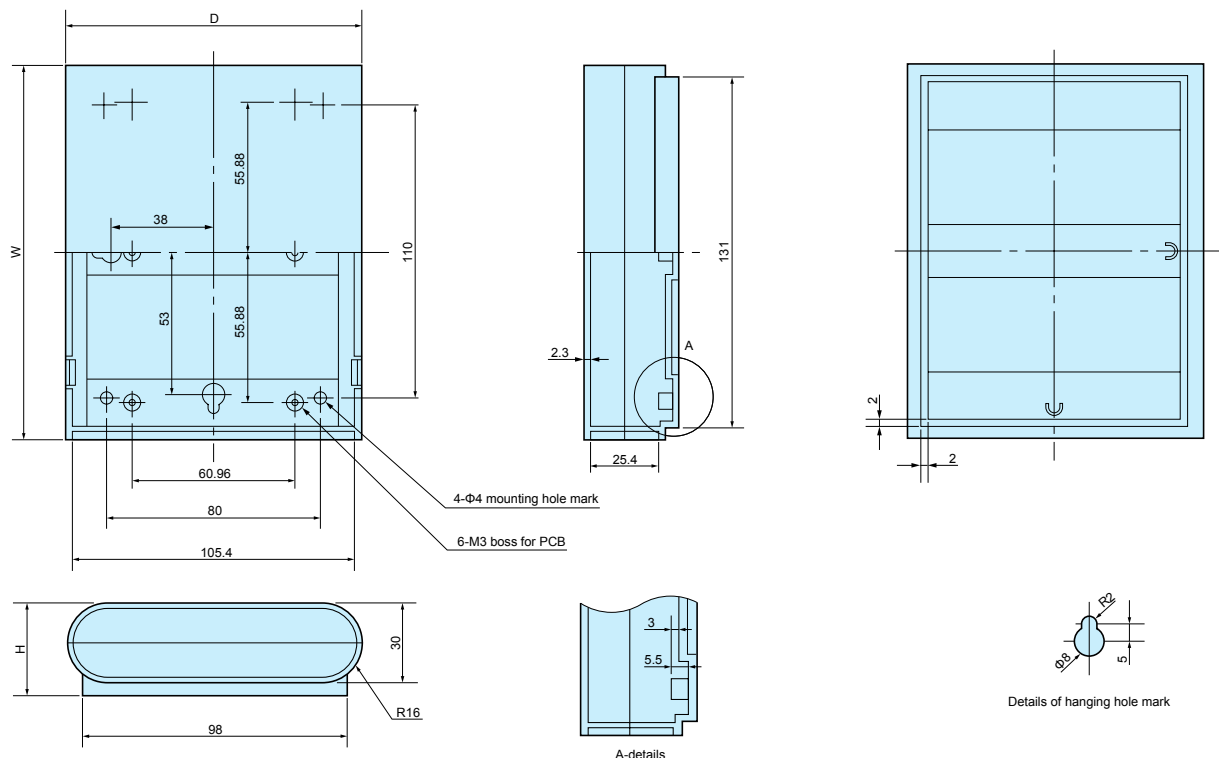

SU-180

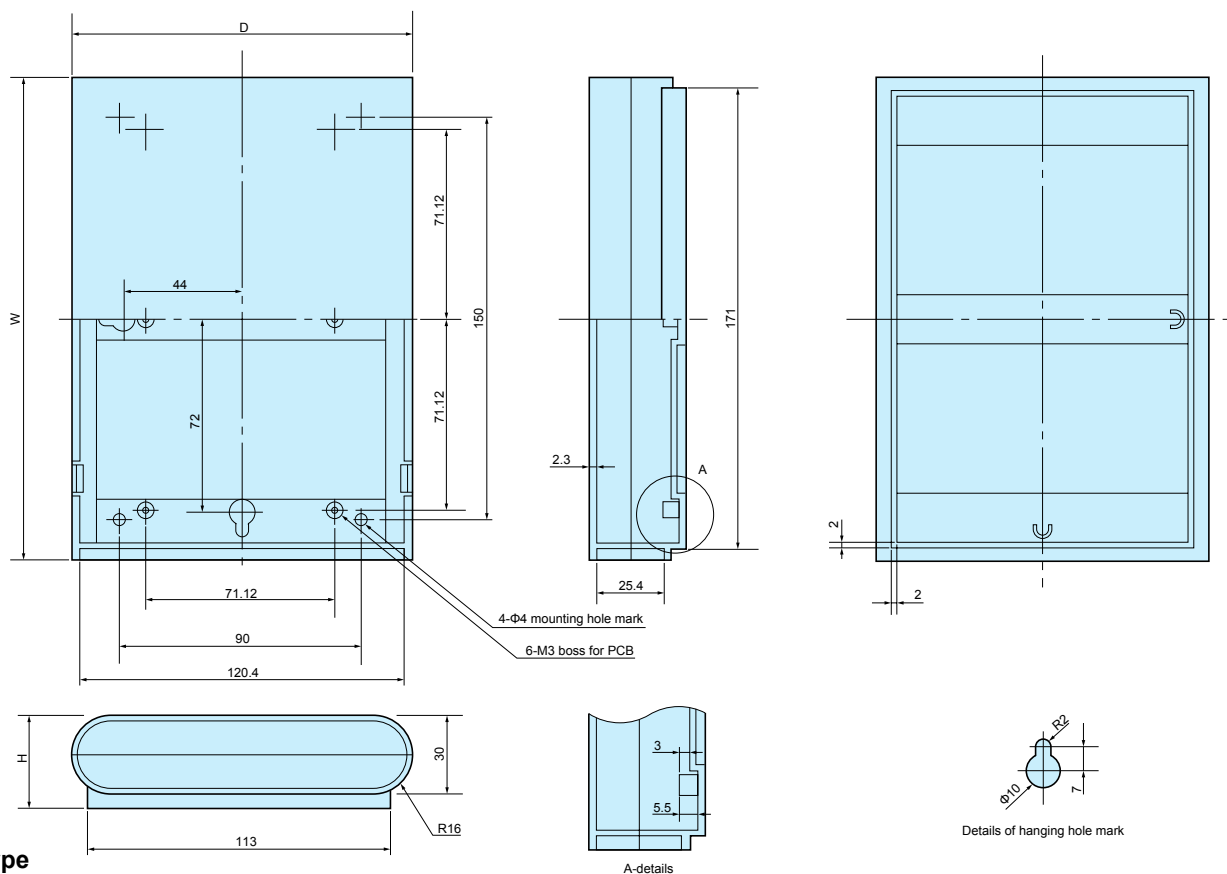

Color Type

Color code	Color
G	Light gray
C	Dark gray
W	White

Part no. / Dimensions

• Please suffix color code at the end of part number □ when ordering SU series.

Part no.	W	H	D	Weight(g)
SU-140□	140	35	110	100
SU-180□	180	35	125	140