

#4129 - FM2R Multi Conductor Cable, 100m reels



Part NO: #4129

Product Code:RGW-1880

Product Description

Reference Standard

Customer's sample spec.and the general standard

Multi-construction

2 Core

Cable Construction

Conductor	Tinned Copper
Construction	T0.20 × 7
Standard Dia.(mm)	0.61
Insulation	HDPE
Thickness	0.3
Insulation Dia.(mm)	1.20 ± 0.05 x 2C
Insulation Color	According to customer
Braiding	Tinned Copper
Construction	T0.1 × 64
Jacket	PVC
Thickness(mm)	0.65
Dia.(±0.15mm)	4.0
Jacket Color	Black

Marking

According to customer


PACKAGING

100M/Wooden Drum

Revision History

A0-1

Design

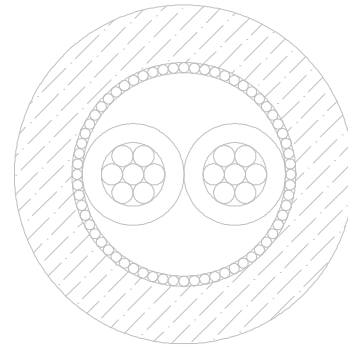

A: Electrical Characteristics

Max.Conductor DC Resistance at 20°C (Ω /Km)	<88.9
Min.Insulation DC Resistance at 20°C (MΩ *Km)	>200
Rated Temperature(°C)	-20 to 80
Rated Voltage (V)	300
Weight	26 kg/Km

RoHS GUIDELINE

We operate according to the following standards

Control Item	Standard	Testing Method	Testing Equipment
Cadmium content (Cd)	<0.01%	EN1122	ICP-AES
Lead content (Pb)	<0.1%	EPA3050B	ICP-AES
Mercury content (Hg)	<0.1%	EPA3052	ICP-AES
Chromium (VI) content	<0.1%	EPA3060(UN-VIS)	ICP-AES
Polybrominated Biphenyls(PBB)	Forbidden	GC/MS	
Polybrominated Diphenyl Ether (PBDE)	Forbidden	GC/MC	

Date: 2013-03-06

Page: 1 / 1