



GE
Lighting

15
kWh/1000h

A+
energy class

96
lumens/watt

T5 LongLast™ - High Efficiency, G5 Cap

FT5/14W/830/GE/LL/SL1/30

61087




Product information

T5 LongLast™ lamps are triphosphor fluorescent lamps with 16mm outer diameter (5/8 of an inch). These lamps feature “Starcoat™ Technology” that delivers high quality triphosphor performance. GE produces two ranges of T5 LongLast™ lamps in 4 different lengths:

- High Efficiency offering high lumens per watt
- High Output offering improved lumen package

Application areas

- Retail
- Office
- Education
- Industrial

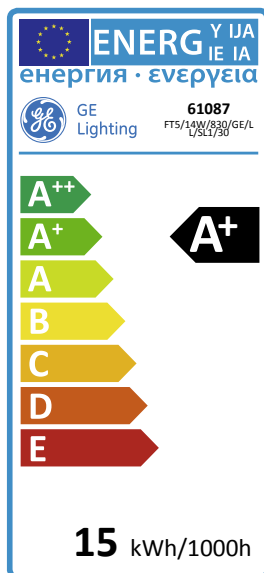

Product data

| | |
|------------------------------------|-----------------------|
| Product Code | 61087 |
| Bulb Shape | Tubular |
| Bulb Diameter [mm] | 16 |
| Regulatory comment | EUP related |
| Bulb maximum overall diameter [mm] | 16 |
| Cap to Cap Length (Max) [mm] | 549 |
| Net weight per piece [g] | 52 |
| Gross weight per piece [g] | 68 |
| Mercury Content [mg] | 2.5 |
| UV radiance | Exempt |
| Brand | General Electric (GE) |
| Cap/Base | G5 |

Performance data

| | |
|--|-------|
| Colour Code | 830 |
| Lumen at 25°C [lm] | 1230 |
| Weighted energy consumption [kWh/1000h] | 15 |
| Rated efficacy [lm/W] | 99 |
| Energy efficiency class (EEC) | A+ |
| Rated Life [h] | 30000 |
| Rated median life on electronic (HF / ECG) ballast on IEC 36000 12-hour cycle | |
| Rated median life on electronic (HF / ECG) ballast on IEC 30000 3-hour cycle | |
| Nominal correlated colour temperature (CCT) [K] | 3000 |
| Nominal lumens [lm] | 1350 |
| Colour Rendering Index (CRI) [Ra] | 85 |


Electrical data

| | |
|--------------------------------------|-----|
| Design Ambient Temperature [°C] | 35 |
| Design Lamp ambient temperature [°C] | 35 |
| Starting ambient temperature range | -15 |
| Dimming Capability | Yes |
| Nominal power [W] | 14 |


Logistic data

| | |
|--------------------------|----------------------|
| DUN Code | 10043168610879 |
| EAN Code | 0043168902397 |
| Pack Quantity | 30 |
| Inner pack type | SLEEVE |
| Outer pack type | OUTER BOX |
| Layer quantity | 360 EUR, 480 UK |
| Layer quantity EUR | 360 |
| Layer quantity UK | 480 |
| Pallet quantity EUR (PC) | 3600 |
| Pallet quantity UK (PC) | 4800 |
| Outer case size | 590 x 120 x 102 (mm) |
| Product status | Available |


Technical drawing

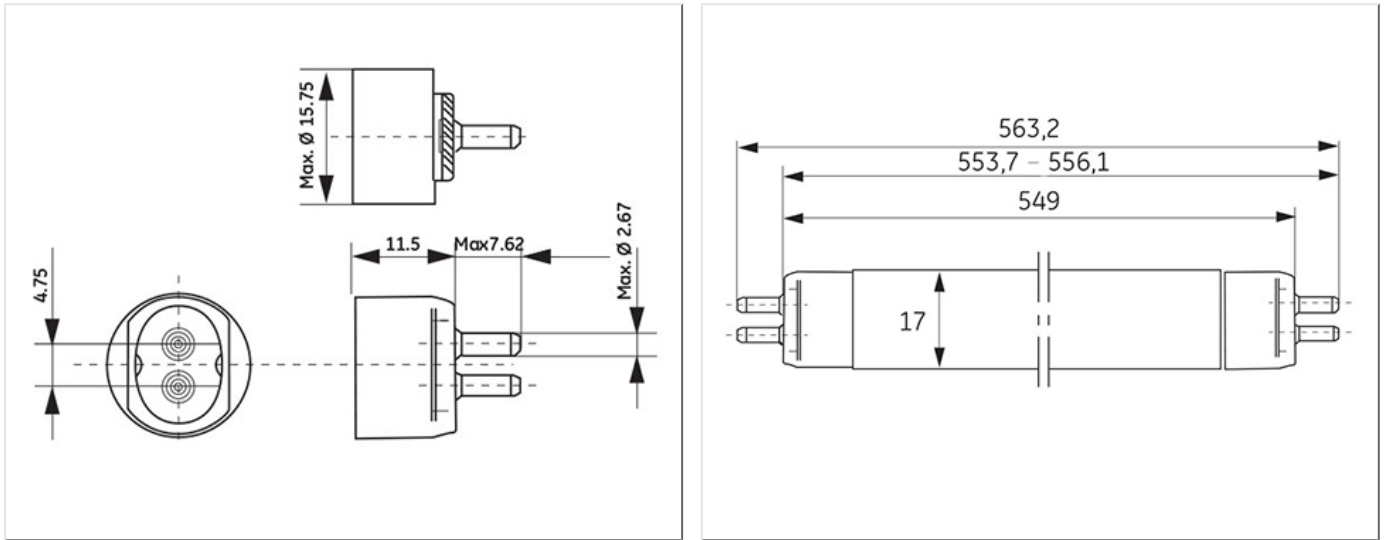


Lumen maintenance data

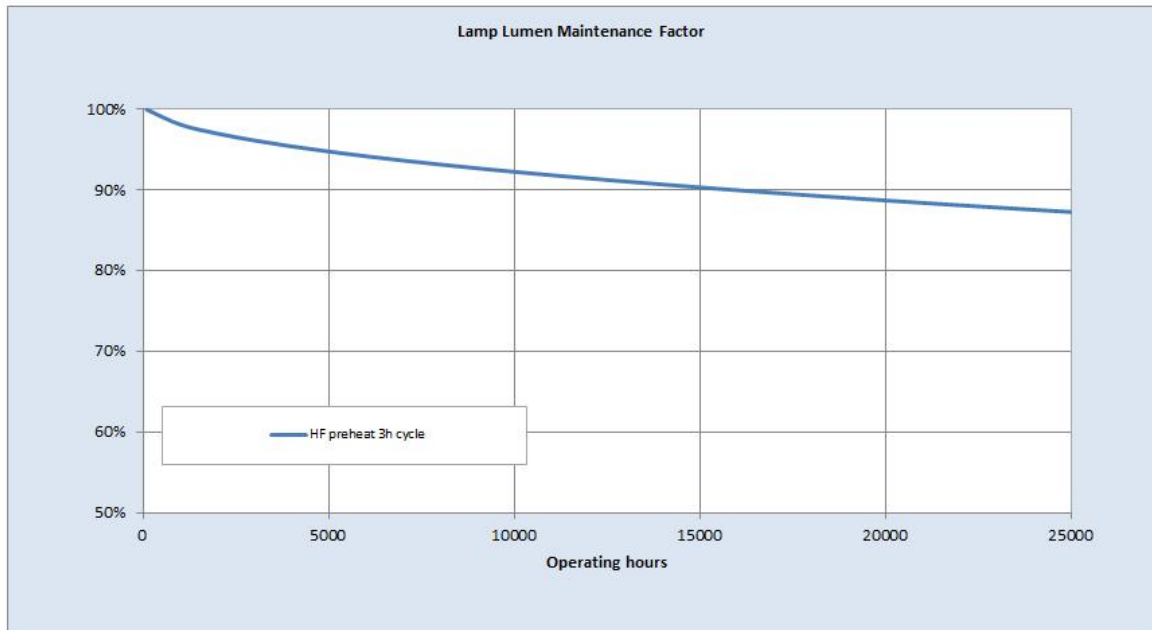

Survival data

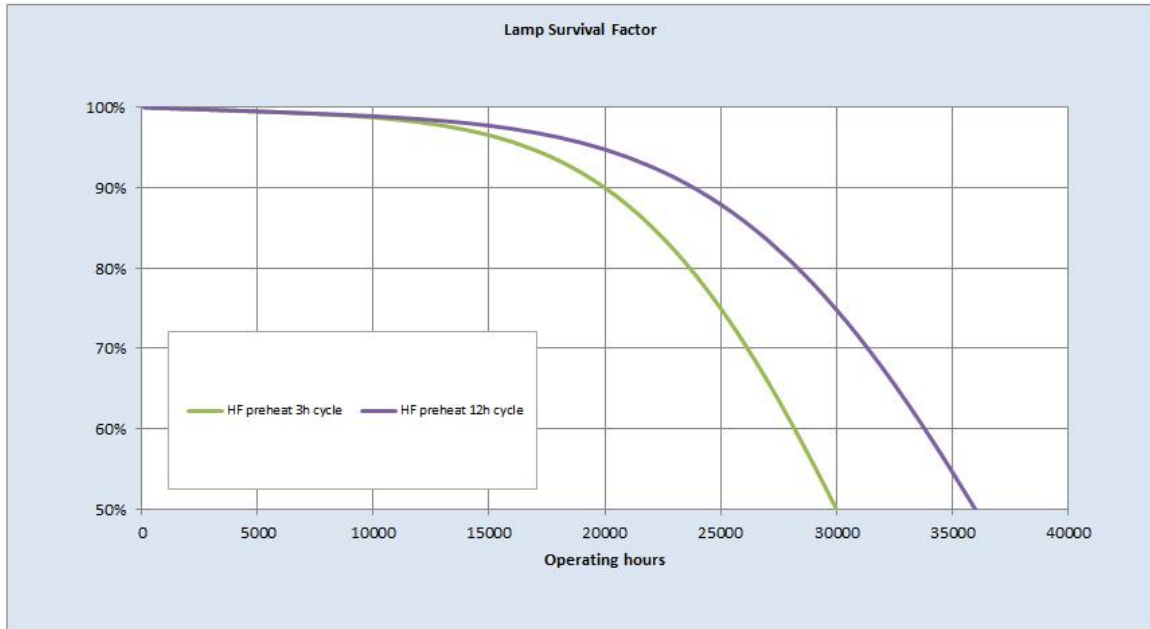

Service life data

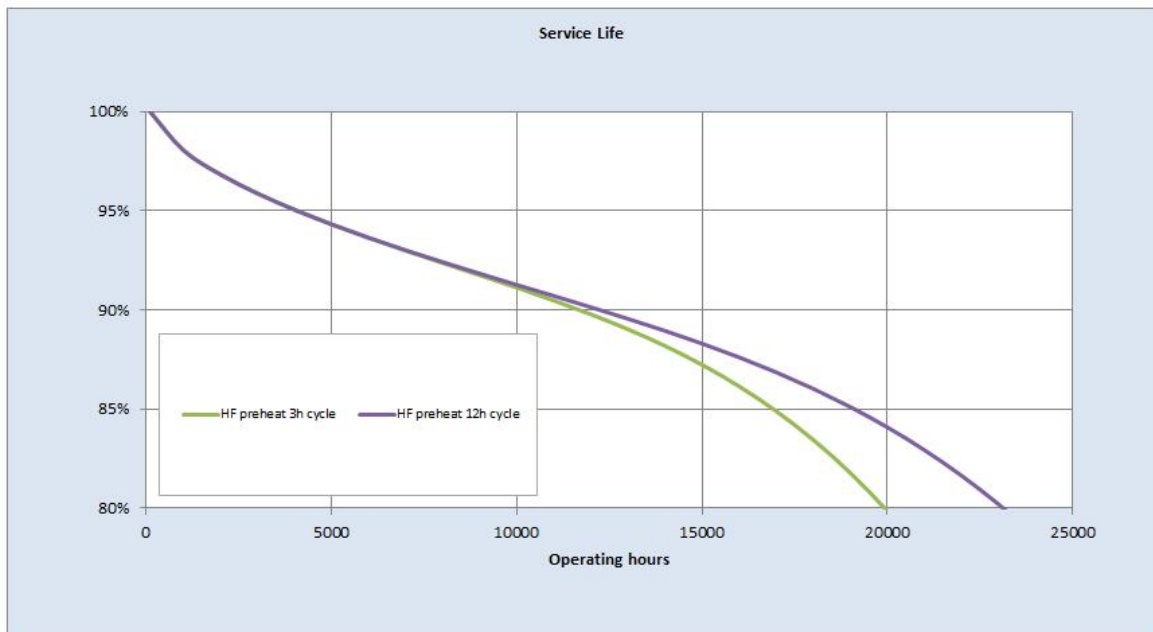

Downloads & Links

[Go to the catalog site \(HTTP\)](#)

[Linear Fluorescent Lamps Catalogue \(PDF\)](#)

[LFL T5 LongLast™ Lamps - Data sheet \(EN\) \(PDF\)](#)

[Lighting design tools & calculators \(HTTP\)](#)

[High-res images / Technical drawings \(HTTP\)](#)

[Certificate for the Quality Management System of GE Lighting EMEA \(PDF\)](#)

[Certificate for the Environmental Management System of GE Lighting EMEA \(PDF\)](#)