



-1. Sockets & accessories

-1.1. SOCKETS 1/2"




Double hexagon

Metric

7800DM

- Standard length sockets, 1/2" square drive
- Bi-hex profile, metric sizes
- Not suitable for machine operation
- High performance alloy steel
- High polished finish
- Knurled
- ISO 2725/1174
- DIN 3124/3120
- SB = Retail packed on a plastic info card

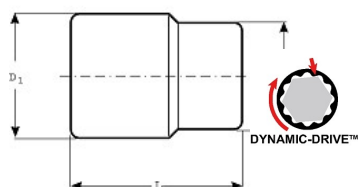



SOCKETS 1/2"



Bahco

				L mm	D1 mm	D2 mm	
7800DM-8	7314151830854	10	8	38	12.9	22.0	42
7800DM-9	7314151830861	10	9	38	14.2	22.0	42
7800DM-10	7314151096991	10	10	38	15.4	22.0	51
7800DM-11	7314151097011	10	11	38	16.6	22.0	51
7800DM-12	7314151097035	10	12	38	17.9	22.0	51
7800DM-13	7314151097059	10	13	38	19.1	22.0	56
7800DM-14	7314151097073	10	14	38	20.4	22.0	56
7800DM-15	7314151097097	10	15	38	21.6	22.0	64
7800DM-16	7314151097110	10	16	38	22.9	22.0	64
7800DM-17	7314151097134	10	17	38	24.1	23.0	72
7800DM-18	7314151097158	10	18	38	25.4	23.5	76
7800DM-19	7314151097172	10	19	38	26.6	24.0	80
7800DM-20	7314151097196	10	20	38	27.9	24.5	81
7800DM-21	7314151097219	10	21	39	29.1	25.0	102
7800DM-22	7314151097233	10	22	39	30.4	25.5	109
7800DM-23	7314151097257	5	23	40	31.6	26.0	109
7800DM-24	7314151097271	5	24	41	32.9	26.5	121
7800DM-25	7314151097295	5	25	42	34.1	27.0	124
7800DM-26	7314151097318	5	26	43	35.4	28.0	136
7800DM-27	7314151097332	5	27	44	36.6	29.0	173
7800DM-28	7314151097356	5	28	45	37.9	27.6	173
7800DM-29	7314151097363	5	29	46	39.1	28.6	175
7800DM-30	7314151097370	5	30	47	40.4	29.5	189
7800DM-32	7314151097387	5	32	47	42.9	30.5	227
7800DM-36	7314151097400	1	36	57	50.0	42.0	315
SB7800DM-8	7314150104437	1	8	38	12.9	22.0	42
SB7800DM-9	7314150104444	1	9	38	14.2	22.0	42
SB7800DM-10	7314150104451	1	10	38	15.4	22.0	51
SB7800DM-11	7314150104468	1	11	38	16.6	22.0	51
SB7800DM-12	7314150104475	1	12	38	17.9	22.0	51
SB7800DM-13	7314150104482	1	13	38	19.1	22.0	56
SB7800DM-14	7314150104499	1	14	38	20.4	22.0	56
SB7800DM-15	7314150104505	1	15	38	21.6	22.0	64
SB7800DM-16	7314150104512	1	16	38	22.9	22.0	64
SB7800DM-17	7314150104529	1	17	38	24.1	23.0	72
SB7800DM-18	7314150104536	1	18	38	25.4	23.5	76
SB7800DM-19	7314150104543	1	19	38	26.6	24.0	80
SB7800DM-20	7314150104550	1	20	38	27.9	24.5	81
SB7800DM-21	7314150104567	1	21	39	29.1	25.0	102
SB7800DM-22	7314150104574	1	22	39	30.4	25.5	109
SB7800DM-23	7314150104581	1	23	40	31.6	26.0	109
SB7800DM-24	7314150104598	1	24	41	32.9	26.5	121
SB7800DM-25	7314150104604	1	25	42	34.1	27.0	124
SB7800DM-26	7314150104611	1	26	43	35.4	28.0	136
SB7800DM-27	7314150104628	1	27	44	36.6	29.0	173
SB7800DM-28	7314150104635	1	28	45	37.9	27.6	173
SB7800DM-29	7314150104642	1	29	46	39.1	28.6	175
SB7800DM-30	7314150104659	1	30	47	40.4	29.5	189
SB7800DM-32	7314150104666	1	32	47	42.9	30.5	227
SB7800DM-36	7314150104673	1	36	57	50.0	42.0	315