


 
# WINSTA® MIDI Distribution Connectors, 3-Pole

	250 V/4 kV/3 $I_N$ 25 A  ① Approvals	250 V/4 kV/3 $I_N$ 25 A  ① Approvals
--	---	---



Description	Color	Item No.	Pack. Unit	Color	Item No.	Pack. Unit
Distribution connectors, pluggable	Distribution connector, 3-way, 1 x plug/3 x socket			Distribution connector, 5-way, 1 x plug / 5 x socket		
	● black	770-607	50	● black	770-608	25
	○ white	770-657	50	○ white	770-658	25
	● red	770-907	50			

Item-Specific Accessories						
	Mounting plate, for distribution connectors			Mounting plate, for distribution connectors		
		black 770-623	25		black 770-623	25
		white 770-673	25		white 770-673	25
	Fixing pin, for mounting plates			Fixing pin, for mounting plates		
		② black 890-601	250		② black 890-601	250
		③ black 770-601	250		③ black 770-601	250
	Lockout cap, for socket, separable, 12-pole			Lockout cap, for socket, separable, 12-pole		
		black 770-201	100		black 770-201	100
		white 770-221	100		white 770-221	100
	Lockout cap, for plug, separable, 5-pole			Lockout cap, for plug, separable, 5-pole		
		yellow 770-360	100		yellow 770-360	100

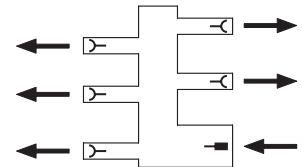

① For "International Certification Organizations" and "Approvals - User Guide," see page 300.

② 5.0 mm Ø, 0.2 ... 1.2 mm plate thickness

③ 6.0 mm Ø, 1 ... 2.5 mm plate thickness

● black Coding A (L ⊕ N)  
 ○ white Coding A (L ⊕ N)  
 ● red Coding P (L ⊕ N)

For coding information, see page 284.  
 Fire load data available upon request.

