


BIG X ADVANCED TECHNOLOGY LEVELS

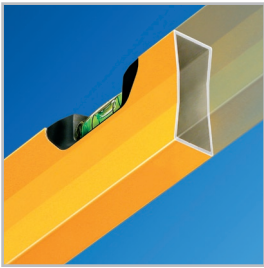

Big X is a new advanced level design with no less than seven innovations designed to make levelling easier and to maintain readability and accuracy over years of use in tough conditions.


BIG X SPECIFICATION

- 630g/m heavy duty 'X' profile.
- Accuracy +/- 0.5mm/m = 0.029° in standard position (+/- 0.75mm/m when inverted).
- One horizontal and two plumb solid block UV and anti-static resistant vials.
- Horizontal vial has luminous backing plate and 30% magnifying lens.
- 360° vial cursor rings.
- Unique temperature tolerant wedge vial construction.
- Shock absorbing rubberised end-caps.
- Vials guaranteed for 30 years against leakage.


PRODUCT CODES

LENGTH

180cm/72in	LX-180
120cm/48in	LX-120
100cm/40in	LX-100
90cm/36in	LX-090
80cm/32in	LX-080

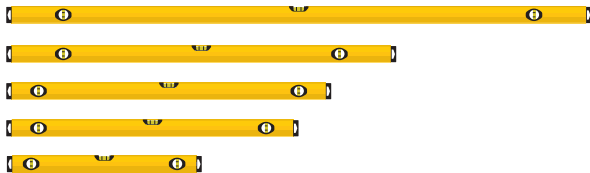

L1 & L1H ULTRA HEAVY DUTY LEVELS

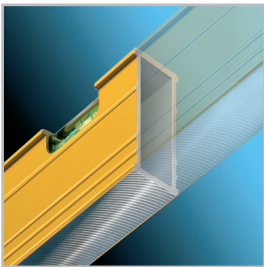

Also available with hand-holds (L1H)



An ultra high specification ultra heavy duty spirit level combining exceptional accuracy and strength with robust durability to satisfy the requirements of the most demanding professional.

L1 SPECIFICATION

- 890g/m ultra heavy duty ribbed profile.
- Accuracy +/- 0.3mm/m = 0.017° in standard position (+/- 0.75mm/m when inverted).
- One horizontal and two plumb solid block UV and anti-static resistant vials.
- Horizontal vial has luminous backing plate and magnifying lens.
- Shock absorbing rubberised end-caps.
- Vials guaranteed for 30 years against leakage.

PRODUCT CODES

LENGTH	L1	L1H
200cm/80in	L1-200	
180cm/72in	L1-180	L1H-180
120cm/48in	L1-120	L1H-120
100cm/40in	L1-100	L1H-100
80cm/32in	L1-080	
60cm/24in	L1-060	

