

Description

TDC10


- Fast Acting
- 1/4" x 1-1/4" physical size
- Glass tube, electroplated brass endcap construction
- Interrupting rating equals 10 times rated current
- Designed to British Standard BS2950A

TDC11


- Time Delay
- 1/4" x 1-1/4" physical size
- Glass tube, electroplated brass endcap construction
- Interrupting rating equals 10 times rated current

Ordering

- Specify packaging and product code

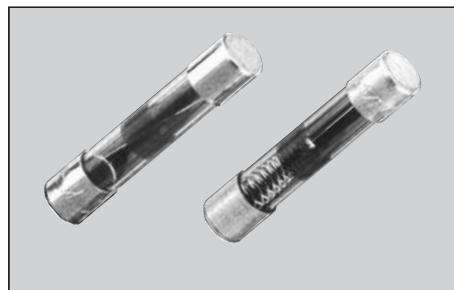

Dimensions mm/(inches)

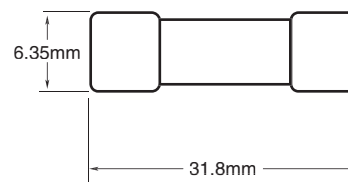

SPECIFICATIONS - TDC10

Product Code	Voltage Rating AC	Interrupting Rating*							
		1000V	750V	500V	350V	250V	150V	100V	32V
TDC10-50MA	1000V	500MA	-	-	-	-	-	-	-
TDC10-60MA	1000V	600MA	-	-	-	-	-	-	-
TDC10-100MA	1000V	1A	-	-	-	-	-	-	-
TDC10-150MA	1000V	1.5A	-	-	-	-	-	-	-
TDC10-250MA	1000V	2.5A	-	-	-	-	-	-	-
TDC10-500MA	750V	-	5A	-	-	-	-	-	-
TDC10-750MA	500V	-	-	7.5A	-	-	-	-	-
TDC10-1A	350V	-	-	-	10A	-	-	-	-
TDC10-1.5A	250V	-	-	-	-	15A	-	-	-
TDC10-2A	250V	-	-	-	-	20A	-	-	-
TDC10-3A	250V	-	-	-	-	30A	-	-	-
TDC10-5A	250V	-	-	-	-	50A	-	-	-
TDC10-7A	150V	-	-	-	-	-	70A	-	-
TDC10-10A	100V	-	-	-	-	-	-	100A	-
TDC10-12A	32V	-	-	-	-	-	-	-	120A
TDC10-15A	32V	-	-	-	-	-	-	-	150A
TDC10-20A	32V	-	-	-	-	-	-	-	200A
TDC10-25A	32V	-	-	-	-	-	-	-	250A



SPECIFICATIONS - TDC11

Product Code	Voltage Rating AC	Interrupting Rating*						
		1000V	750V	500V	350V	250V	150V	100V
TDC11-50MA	1000V	500MA	-	-	-	-	-	-
TDC11-60MA	1000V	600MA	-	-	-	-	-	-
TDC11-100MA	1000V	1A	-	-	-	-	-	-
TDC11-150MA	1000V	1.5A	-	-	-	-	-	-
TDC11-250MA	1000V	2.5A	-	-	-	-	-	-
TDC11-500MA	750V	-	5A	-	-	-	-	-
TDC11-750MA	500V	-	-	7.5A	-	-	-	-
TDC11-1A	350V	-	-	-	10A	-	-	-
TDC11-1.5A	250V	-	-	-	-	15A	-	-
TDC11-2A	250V	-	-	-	-	20A	-	-
TDC11-3A	250V	-	-	-	-	30A	-	-
TDC11-5A	250V	-	-	-	-	50A	-	-
TDC11-7A	150V	-	-	-	-	-	70A	-
TDC11-10A	100V	-	-	-	-	-	-	100A

* Interrupting Rating: Interrupting rating is 10 times the rated current.

** DC Cold Resistance (Measured at <10% of rated current)

TIME CURRENT CURVE

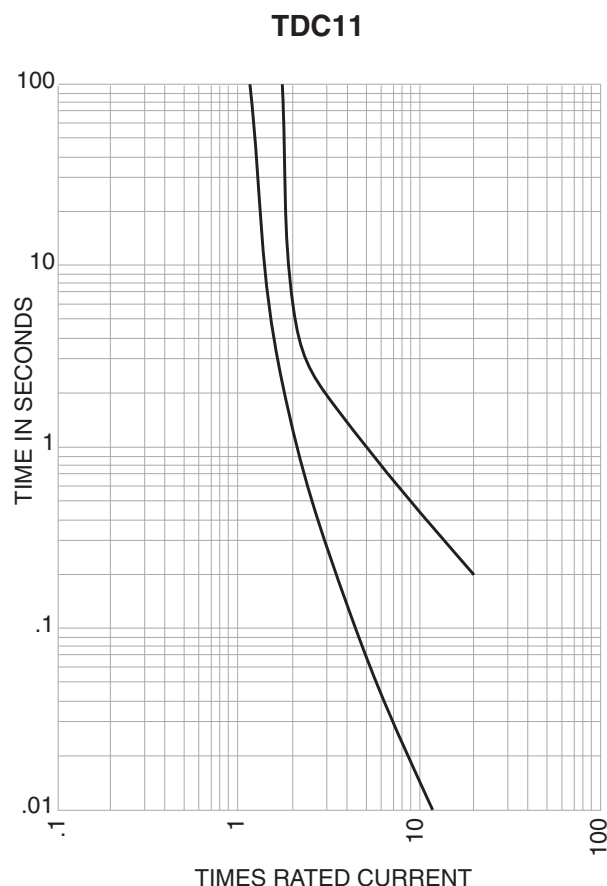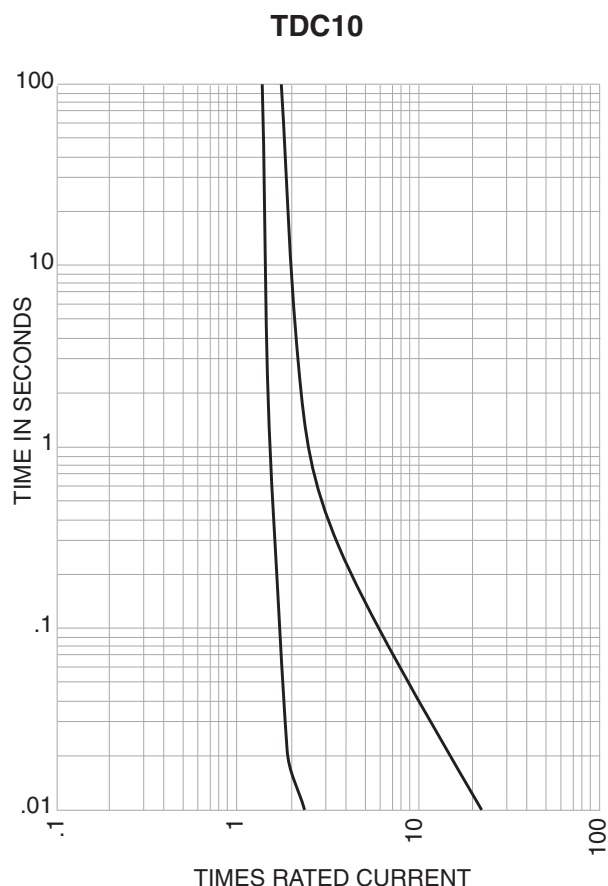

PACKAGING CODE

Packaging Code	Description
BK	100 pieces of fuses packed into a cardboard carton
BK1	1,000 pieces of fuses packed into a cardboard carton

North America

Cooper Electronic Technologies
1225 Broken Sound Parkway NW
Suite F
Boca Raton, FL 33487-3533
Tel: 1-561-998-4100
Fax: 1-561-241-6640
Toll Free: 1-888-414-2645

Cooper Bussmann
P.O. Box 14460
St. Louis, MO 63178-4460
Tel: 1-636-394-2877
Fax: 1-800-544-2570

Europe

Cooper Electronic Technologies
Cooper (UK) Limited
Burton-on-the-Wolds
Leicestershire • LE12 5TH UK
Tel: +44 (0) 1509 882 737
Fax: +44 (0) 1509 882 786

Cooper Electronic Technologies
Avda. Santa Eulalia, 290
08223
Terrassa, (Barcelona), Spain
Tel: +34 937 362 812
+34 937 362 813
Fax: +34 937 362 719

Asia Pacific

Cooper Electronic Technologies
1 Jalan Kilang Timor
#06-01 Pacific Tech Centre
Singapore 159303
Tel: +65 278 6151
Fax: +65 270 4160