



## Datasheet

ENGLISH

# SL SLIMLINE TRUNKING IN PVC-U



SL slimline trunking is suitable for domestic and light commercial installations including hotels. It is of particular interest for those faced with the challenge of achieving unobtrusive re-cabling in refurbishment projects.

- Available in 70x20 & 110x20mm
- Base is pre-punched, which facilitates speedy positioning and installation
- Although slim line in design, the SL range can still address the need to segregate high and low voltage circuits

**Standard supply:**

Base and cover packed together

**Material:**

Cover - PVC-U 1309

Base - PVC-U 1530

**Supplied length:**

2 mtr

**Sizes:**




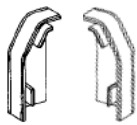


Available in two dimensions

- 70x20mm and 110x20mm

**Colour:**

RAL 9010 Pure White



		SL Skirting Trunking	SL Skirting Trunking
	Height/Width	70x20	110x20
Base & Cover	<u>RAL 9010 Pure White RS Stock No.</u>	787-4527	787-4520
			
Internal Corner	<u>RAL 9010 Pure White RS Stock No.</u>	787-4524	787-4552
			
External Corner	<u>RAL 9010 Pure White RS Stock No.</u>	787-4533	787-4561
			
End Caps Right/Left	<u>RAL 9010 Pure White RS Stock No.</u>	787-4536	787-4564
			
Coupler	<u>RAL 9010 Pure White RS Stock No.</u>	787-4530	787-4568
			
Single Socket Outlet Box	<u>RAL 9010 Pure White RS Stock No.</u>	787-4549 (UK Standard) 787-4546 (Euro Standard) 787-4555 (45mm Insert Standard)	787-4577 (UK Standard) 787-4574 (Euro Standard) 787-4583 (45mm Insert Standard)
			
Double Socket Outlet Box	<u>RAL 9010 Pure White RS Stock No.</u>	787-4542 (UK Standard) 787-4558 (Schuko Standard)	787-4570 (UK Standard) 787-4586 (Schuko Standard)
			