

F10-RGB5050-24-60-IP65 are High Power RGB IP65 Rated LED Flexible Strips suitable for domestic, commercial and retail internal lighting applications.

- Energy Saving
- Compact strip with SMD LED Technology
- Water Resistant to IP65 level*
- 50k hours working life
- High Reliability
- High Efficiency
- 60 LEDs per metre
- Cuttable every 100mm
- 120° beam angle

Applications


- Accent Lighting
- Cabinet Lighting
- Mood Lighting
- Cove Lighting
- Under Cabinet Lighting
- Bookshelf Lighting
- Display Cabinet Lighting

High Power RGB IP65 Rated Energy Saving LED Flexi Strip




★ Flexi Strip Specification

Part Number	F10-RGB5050-24-60-IP65
Power	14.4W per metre
Input	24V
LEDs Per Meter	60
Cuttable Length	every 100mm
IP Rating	IP65
Colour	RGB
Lumens	500lm/metre
Length	5 Metres
Weight	250g

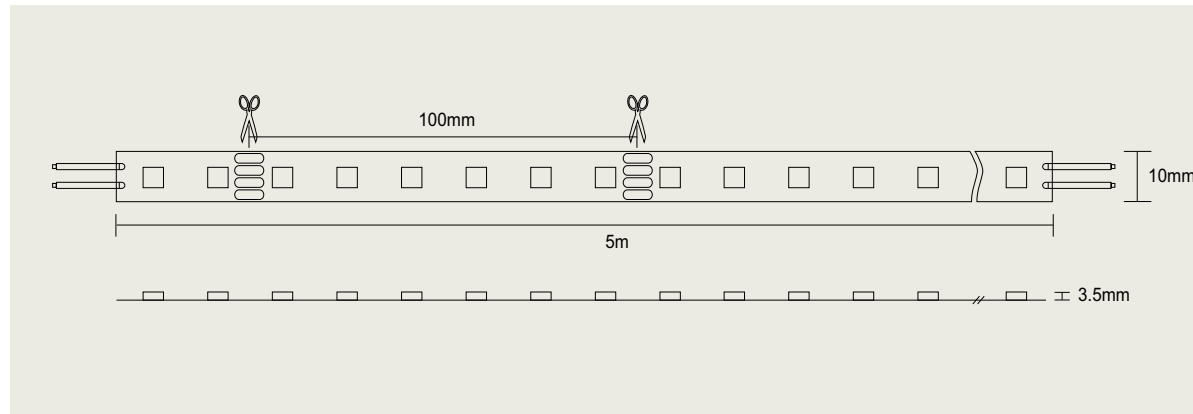

IP65

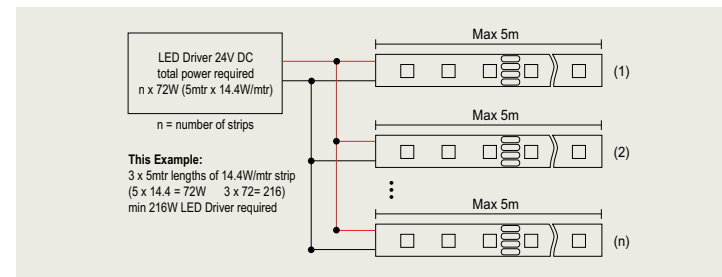

We recommend a maximum of 15mtrs strip per driver due to possible voltage drop

*Product not fully IP65 Rated unless IP65 Rated connections & power supply used
Representative colours may change; purchase from the same batch code for colour consistency