

VS-PC-2XPOF-980-SCRJ/SCRJ-1

Order No.: 1656738



Assembled fiber optic cable, break-out cable, polymer fiber 980/1000 µm, SCRJ/IP20 on SCRJ/IP20, for installation inside control cabinets, length: 1 m

**Commercial data**

EAN	4046356030052
Pack	1 Pcs.
Customs tariff	85369010
Weight/Piece	0.0449 KG
Catalog page information	Page 189 (PC-2007)

Product notes

WEEE/RoHS-compliant since:
05/15/2006

**Technical data****Mechanical characteristics**

Number of positions	2
Connection profile	SCRJ according to DIN EN 50377-6-1
Fiber type	Polymer Fiber
Fiber	980/1000 µm


Ferrule diameter	2.50 mm
Number of fibers	2
Insertion/withdrawal cycles	≥ 1000
External cable diameter	Twin conductor (2.2 x 4.4 mm)
Type of cable	Break-out cable
Smallest bending radius, fixed installation	30 mm
Smallest bending radius, movable installation	30 mm
Length of cable	1 m
Ambient temperature (operation)	-20 °C ... 70 °C

Material data


Housing material	PBT
Outer sheath, material	PE
External sheath, color	black
Ferrule material	Copper alloy
Ferrule holder color	Blue
Degree of protection	IP20

Drawings

Dimensioned drawing

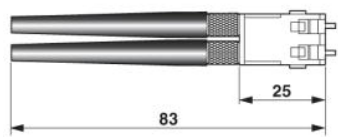

SCRJ plug connector, POD, IP20

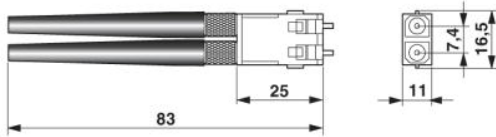

SCRJ plug connector, POD, IP20