


FUSES & FUSEHOLDERS

5x20mm Fused Terminal Blocks

- 1 - 5 pole terminal strip with 5x20mm fuseholder to IEC257
- Integral spare fuse carrier
- Interlocking fuseholder with CFTBN/1
- Anti rotation spigot
- IP20 finger protection
- Cable entry 4mm² (2.5mm² with wire protector)
- Wire protector on fuse terminal as standard
- Standard 3 to 5 pole with earth screw, without wire protectors
- Version 2 to 5WP without earth, with wire protector on all poles
- Version 3 to 5EWP with earth, wire protector on all poles except earth
- Version 3 to 5NE without earth, without wire protectors
- Wire protectors on earth pole to order
- Meets creepage and clearance requirements of IEC (8mm)
- 16mm fixing pitch
- Easily cut to size
-  FIMKO, approved, on non earth versions


CFTBN




TYPE NO.	POLES
CFTBN/1	1 interlocking
CFTBN/2	2
CFTBN/3	3 with earth screw
CFTBN/4	4 with earth screw
CFTBN/5	5 with earth screw
CFTBN/3NE	3 no earth facility
CFTBN/4NE	4 no earth facility
CFTBN/5NE	5 no earth facility
CFTBN/2WP	2 with wire protector & no earth facility
CFTBN/3WP	3 with wire protector & no earth facility
CFTBN/4WP	4 with wire protector & no earth facility
CFTBN/5WP	5 with wire protector & no earth facility
CFTBN/3EWP	3 with wire protector & earth screw (no WP on earth connection)
CFTBN/4EWP	4 with wire protector & earth screw (no WP on earth connection)
CFTBN/5EWP	5 with wire protector & earth screw (no WP on earth connection)
CFTBN/3EWPG	3 with wire protection on all poles & earth screw
CFTBN/4EWPG	4 with wire protection on all poles & earth screw
CFTBN/5EWPG	5 with wire protection on all poles & earth screw

SPECIFICATION

Rating	Fuseholder 250V AC Terminal 450V AC
Current rating	Fuseholder 13A Terminal 20A
Moulding	UL94-V0 flame retardant PA
Terminal	Brass, nickel plated
Fuse clip	Phosphor bronze
Wire protector	Stainless steel
Temperature	-20° to 120°C
Fuse size	5x20mm glass or ceramic
Screws	M3

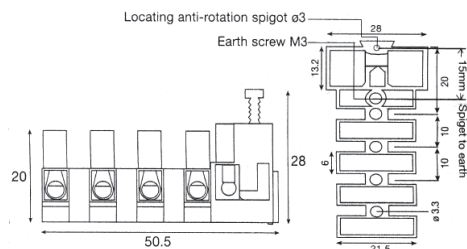

On CFTBN/1 spigot to mounting hole = 10mm

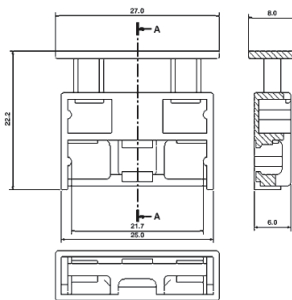

Terminal Cover

- Screw / dust protection
- Easily cut to required size



TYPE NO.	POLES
CFTBN/3C	3 pole cover
CFTBN/5C	5 pole cover