


**65846-008LF - Mini-PV™, Basics+ : 2.54 x 2.54 mm (0.1 x 0.1 in.) Centerline Crimp-to-Wire PV Receptacle Housing, Double Row, Polarized**

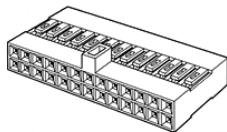

[www.fci.com](http://www.fci.com)

## Mating Half

☒ 69168-118HLF

☒ 78207-118HLF

☒ 67996-118HLF

☒ 68020-118HLF

## Specifications

### Approvals / Certifications

<b>UL File Number</b>	E66906
<b>CSA File Number</b>	LR46923
<b>Approvals / Certifications</b>	UL and CSA Approved
<b>Dimensional</b>	
<b>Length (Mating pin)</b>	5.33 mm (0.21 in.) to 6.1 mm (0.24 in)
<b>Size (Wire)</b>	22 to 36 AWG
<b>Electrical</b>	
<b>Resistance (Insulation)</b>	100000 M-ohms
<b>Voltage rating</b>	1000V rms
<b>General</b>	
<b>Number of contacts</b>	18
<b>Number of rows</b>	2
<b>Orientation</b>	Vertical
<b>Product Type</b>	Crimp-to-Wire Housing
<b>Polarization (Key)</b>	Yes
<b>Mating half</b>	Mates with 0.64 mm (0.025 in.) Square Pin with Length of 5.33 mm (0.21 in.) min. to 6.1 mm (0.24 in.) max.
<b>Series Number</b>	65846
<b>Other Features</b>	
<b>Accessory</b>	Polarization Plug 65307-001LF
<b>Packaging (Type)</b>	Bag
<b>Comments</b>	PV™ Contact Removal Tool: Part Number HT-0080
<b>Physical</b>	
<b>Color (Housing)</b>	Black
<b>Material (Housing)</b>	PPE+PS
<b>Temperature (Operating - range)</b>	-40°C to +105°C