

Standard Buccaneer®


Buccaneer® Connectors



- Contacts for 25 Way Inserts
- Crimp or Solder Pins and Sockets
- 1A, 50V

Contacts - Solder & Crimp

Contacts (Supplied in packs of 10)	Solder	Crimp
Pins	SA3180/1	SA3180
Sockets	SA3179/1	SA3179

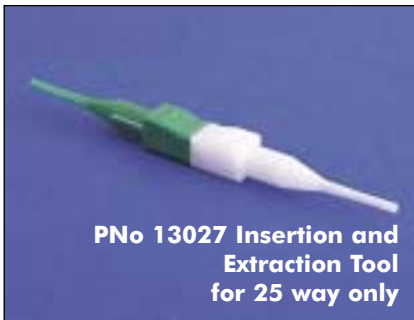

- Insertion and Extraction Tool
- For Use with 25 Way Inserts

Tools

Crimp Tool (25 Way)	PNo. 13170
Crimp Tool (9 Way)	PNo. 13826
Insertion/Extraction Tool (25 Way)	PNo. 13027
Hex Cavities for BNC Inserts Centre Contact:	1.69 A/F (B.S. 'W'/ERMA XA)
Braid:	6.48 A/F (B.S. 'E'/ERMA XH)



- BNC Inserts
- 50 or 75 ohms available
- Fit all Standard Connector Versions

Cable Acceptance - Standard as supplied

No. Contacts	Cable Diameter
2-9 Pole	6-8mm
25 Pole	7-9mm
BNC	RG 58/CU, URM43, URM76, URM70

Cable Acceptance - Alternatives

Cable Diameter	Gland Part No.	Gland Colour	Additional Suffix
6-8mm	12023	Black	Standard for 2-9 pole
3.5-5mm	12023/5	Grey	Suffix /04
5-7mm	12023/1	White	Suffix /05
7-9mm	12023/2	Yellow	Suffix /07
Gland Pack	SA3253		Pack of 3 glands to suit cables 3.5-5mm, 5-7mm & 7-9mm dia

To order connector with alternative cable gland add suffix to part no. e.g. PX0731/P/07 = PX0731 connector with cable gland to suit 7-9mm dia. cable.



- Sealing Cap Assembly Tools to Maintain IP68 Rating of Unmated Connectors
- Seals Connector and Removes Inserts
- Two Styles, One for Flex Mount and One for Chassis Mount & Flex In-Line Connector

