

SKBI 64/C32

Order No.: 2265034



Plug-in card block, Nominal current: 1 A, Number of positions: 64,
Pitch: 0 mm, Connection method: Screw connection, Color: green

Commercial data

EAN	4 017918 053932
Pack	1
Customs tariff	85369010
Country of Origin	DE
Catalog page information	Page 551 (CC-2011)

Product notes

WEEE/RoHS-compliant since:
07/06/2006



Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation at <http://www.download.phoenixcontact.com>. The General Terms and Conditions of Use apply to Internet downloads.

Technical data**Dimensions / positions**

Length	66 mm
Height	162 mm
Width	118 mm
Pitch	0 mm
Number of positions	64

Hole diameter	4.2 mm
Screw thread	M3
Tightening torque, min	0.5 Nm
Tightening torque max	0.6 Nm

Technical data

Range of articles	SKBI 64
Connection in acc. with standard	EN-VDE
Nominal current I_N	1 A
Nominal voltage U_N	250 V (surge voltage category III/contamination class 2)
Nominal cross section	2.5 mm ²
Stripping length	8 mm

Connection data

Conductor cross section solid min.	0.2 mm ²
Conductor cross section solid max.	4 mm ²
Conductor cross section stranded min.	0.2 mm ²
Conductor cross section stranded max.	2.5 mm ²
Conductor cross section AWG/kcmil min.	24
Conductor cross section AWG/kcmil max	12

Certificates



Certification


GOST

Accessories

Item	Designation	Description
Assembly		
2263007	SF-SKBI 64	Snap foot, for horizontal or vertical mounting of the SKBI plug-in card blocks, on the NS 35/7.5 DIN rail

Drawings

Dimensioned drawing

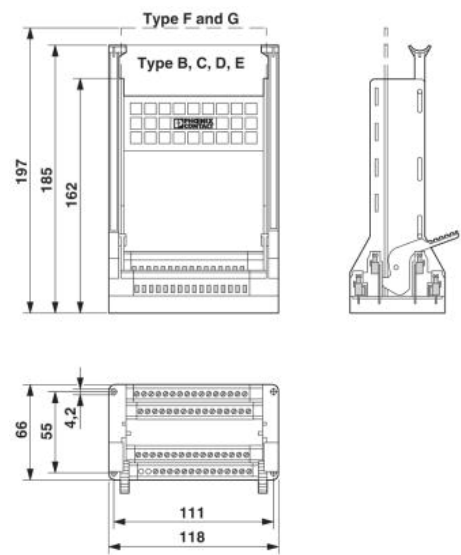

Schematic diagram

