



ENGLISH


Datasheet

New 5.08mm Plug with Flanges 15A 6 way

RS Stock 874-4758



Dimensions: (mm)

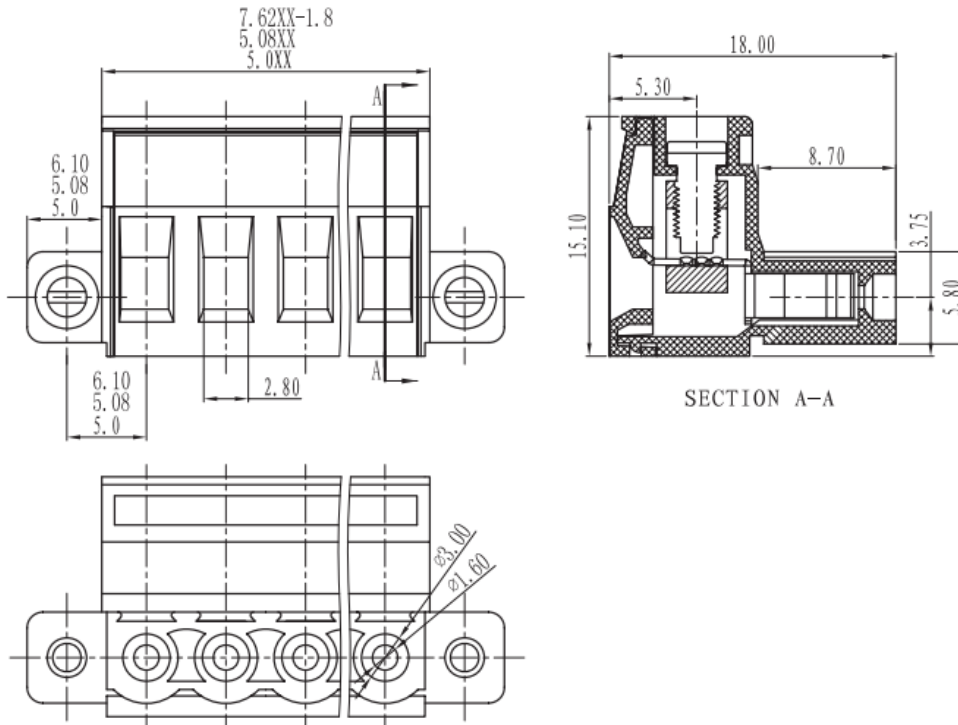



ENGLISH

Specifications

Electrical

Standard:	UL	IEC
Rated voltage:	300V	320V
Rated current:	15A	20A
Contact resistance:	20m Ω	
Wire range:	28-14AWG	2.5mm ²
Withstanding voltage:	AC2000V/1Min	
Insulation resistance:	500M Ω /DC500V	

Mechanical

Temp.Range:	-40° C~+105° C
Torque:	0.5Nm (4.51lb`in)
Strip length:	7-8mm

Dimensions

Pitch:	5.00mm, 5.08mm, 7.62mm
Poles:	2P-24P

Material

Housing:	PA66, UL94V-0
Screws:	M3.0, steel Zinc plated
Wire guard:	Brass, Ni plated
Clamp:	Phosphor bronze, Ni plated