


Datasheet

LED Cluster Lamp, Warm White, 60 mA, 230 V ac

RS Stock 720-3789

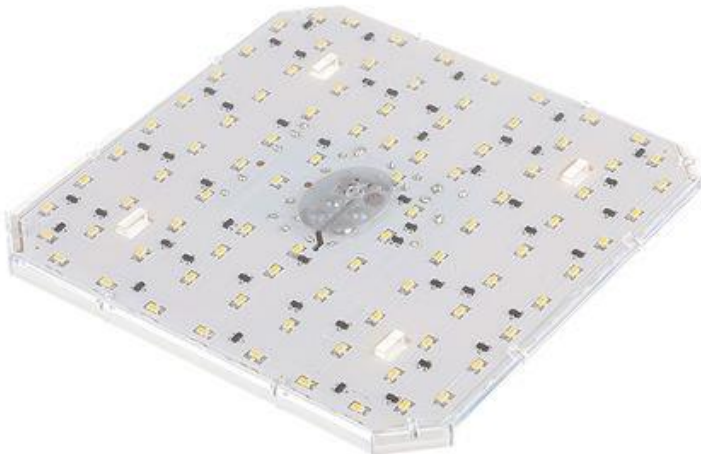

Specification:

Lamp

Colour Temperature

Pure White (5000°K)

Warm White (3250°K)

Lamp Life

up to 50,000 hours

Built in redundancy against LED failure

Environmental

Operating Temperature

-20°C...+30°C

Storage Temperature

-40°C...+65°C

Relative Humidity

0% to 90% Non-condensing

Materials

Case

Flame-retardant ABS V0 rated

Lens

Polycarbonate V2 rated

Voltage & Connection

230 V ac +/- 5% (see label), 50 Hz

Internal fuse protection

200mA (not user replaceable)

Remove the starter and any power factor capacitor installed in the fitting. **Any modification required to the fitting should be undertaken only by a qualified electrician.** The owner/ installer must satisfy themselves that the lamp is suitable for use and may be used safely in a given fitting.

Design & Manufacture

Designed & manufactured to ISO 9001:2008. Quality Assurance Standard and tested for compliance with European CE Certification for use across the European Union. RoHS compliant. All specifications and images are subject to change without notice.