

Product Information



3477UOO080P30-13

EAN 4031582306125


Swivel castor with total lock, tail end of castor, housing made of pressed steel, bright zinc plated, blue passivated, double ball bearing swivel head, wheel axle with nut, bolt hole.

Wheel centre made of Polyamide, plain bearing

Technical Data

Wheel diameter	80 mm
Width of Tread	34 mm
Centre hole	13 mm
Offset	44.5 mm
Swivel Interference	242 mm
Overall height	108 mm
Temperature	- 20 / + 60 °C
Standard	EN 12532
Weight	0.873 kg
Swivel Radius	121 mm
Hardness of tread	D 75 Shore
Load capacity	150 kg
Load capacity (static)	300 kg

Roll performance	+	+	+	+	+
Movement noise	+	+	+	+	+
Attrition	+	+	+	+	+
Corrosion resistance	+	+	+	+	+

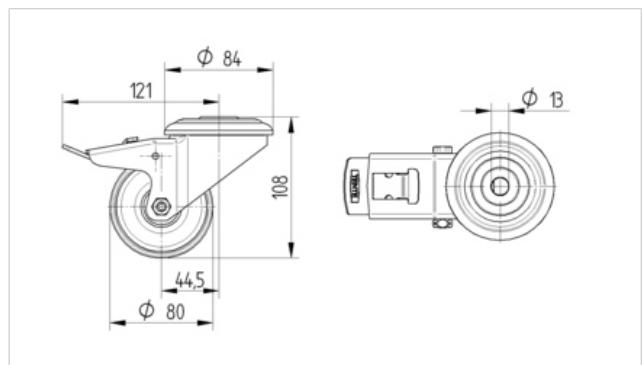

3477UOO080P30-13

EAN 4031582306125

