




**V\*fast® Valve Connectors w/Integral eurofast or picofast Connector**

- Integral *eurofast*® and *picofast*® Connectors
- Compact Size
- Black Body
- 2 Conductors + Ground (*eurofast*)




\*\*All parts except *eurofast*.

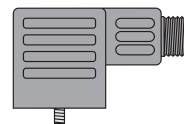

*eurofast*

**“A” Style Valve Connectors, Integral eurofast Connector**

 Application	Pinout	Voltage VAC/DC	Straight Wired	Indicator LED	Indicator LED and MOV
“A” Style Connector with Integral <i>eurofast</i> connector 2 Conductors, 1 Ground Ground contacts Parallel wired	<pre> 1  ────&gt; 4 2  ────&gt; 3 GND ────&gt; 5 GND ────┘                     </pre>	0-220 24-48	VAS 22-A-FS 5.3 - - - -	- - - - - - - -	- - - - VAS 22-D-FS 5.3



*picofast*

**“A”, “B”, and “I” Style Valve Connectors with Integral picofast Connector**

Application	Pinout	Voltage VAC/DC	Straight Wired	Indicator LED	Indicator LED and MOV**
“A” Style Connector with Integral <i>picofast</i> connector 2 Conductors	<pre> 1  ────&gt; 4 2  ────&gt; 3 GND ────&gt; NC GND ────┘                     </pre>	0-60 24-48	VAS 22-A-V1131 - - - -	- - - - VAS 22-B-V1131	- - - - VAS 22-D-V1131
“B” Style Connector with Integral <i>picofast</i> connector 2 Conductors	<pre> 1  ────&gt; 4 2  ────&gt; 3 GND ────&gt; NC                     </pre>	0-60 24-48	VBS 2-A-V1131 - - - -	- - - - VBS 2-B-V1131	- - - - VBS 2-D-V1131
“I” Style Connector with Integral <i>picofast</i> connector 2 Conductors	<pre> 1  ────&gt; 4 2  ────&gt; 3 GND ────&gt; NC                     </pre>	0-60 24-48	VIS 2-A-V1131 - - - -	- - - - VIS 2-B-V1131	- - - - VIS 2-D-V1131