


Tapered roller bearings, single row

Principal dimensions			Basic load ratings		Speed ratings	Limiting speed	Designation
d	D	T	dynamic C	static C0	Reference speed		* SKF Explorer bearing
mm			kN		r/min		-
31,75	62	19,05	48,4	57	8000	12000	15123/15245/Q

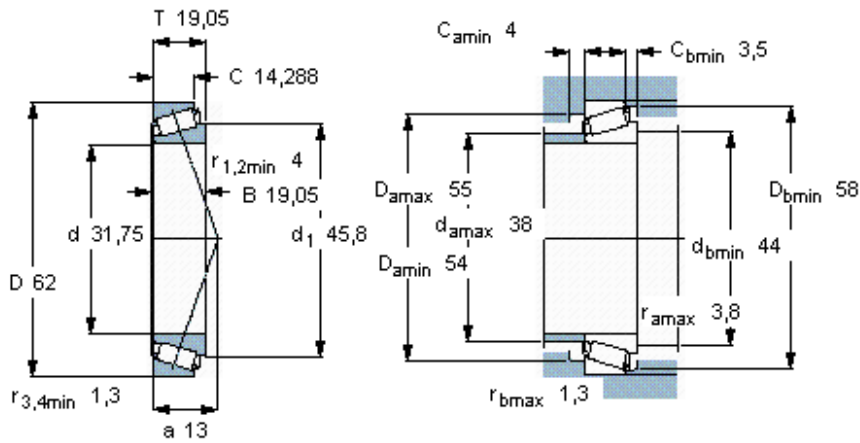

Calculation factors

$e = 0,35$

$Y = 1,7$

$Y_0 = 0,9$