

Datasheet

RS Pro BA9s Filament Indicator Lamp, Clear, 24 V, 50 mA, 5000h

RS Stock No: **105-095**



Product Details

RS Pro BA9s filament indicator lamp comes with clear lens. It performs at a voltage rating of 24 V and current rating of 50 mA. The lamp has 5000 h life. This tubular MCC lamp is suitable for applications in the automotive and gambling machine industries.

Features and Benefits

- Voltage rating of 24 V
- Current rating of 50 mA
- 5000 hours lifetime




Specifications:

Current Rating	50 mA
Diameter	10.5 mm
Lamp Base	BA9s
Lamp Size	T3 1/4
Length	29 mm
Lens Colour	Clear
Life Hours	5000 h
Luminosity	4 lm
Voltage Rating	24 V

RS Stock No.	105095
--------------	--------

DRAWING - I

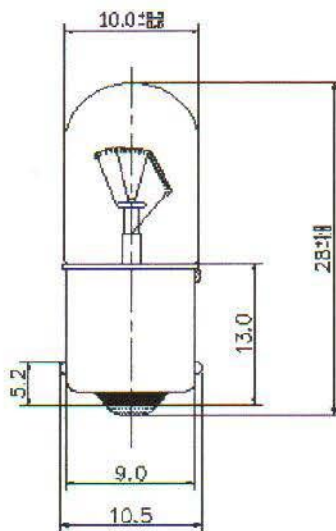

Unit : mm

1. Structure	Bulb Type	T3 1/4 Clear
	Bulb Diameter	Ø10.5Max.
	Length	29.0Max
	Base Type	Ba9s.
2. Design Characteristics	Voltage	24V
	Amperage	50mA±10%
	Filament Type	Vacuum type
	Luminous Flux	4Lm±20%
	Life Hours	5,000Hrs