

# LEDs & INDICATORS


## 501 SM Series

- Press fit body for various panel thicknesses, panel cut-out 8mm diameter
- Stripped 10mm wire termination 162mm long as standard
- Neons 125-240V 0.8-1mA, as standard
- Pin termination to order
- LED, Filament 6-28V 30-40mA to order
- Pin termination available on low voltage LED and filament, lenses 1-3
- Polycarbonate lens/body
- Maximum working temperature 105°C
- Red, green, amber lens colour options as standard
- Other lens colour options to order
- Three round lens styles options as standard and one square style to order
- Custom wire lengths and specification to order




TYPE NO.	501	X	XX-XXXX	- T /	XXX
501 Series Indicator	501				
Lens cylinder top-hat	1				
Lens cylinder low profile	2				
Lens cylinder tapered sides	3				
Lens square low profile	4				
Stripped wire 162mm long	05				
Pin termination	13				
LED, white cathode & black anode wires	LED				
Filament 6V 40mA, white wire	640				
Filament 14V 40mA, yellow wire	1440				
Filament 24V 35mA, green wire	24				
Filament 28V 30mA, green wire	28				
Neon 125V 1mA, blue wire	125				
Neon 240V 0.8mA, red wire	240				
Transparent lens	T				
Lens colour Red	RED				
Lens colour Green	GRN				
Lens colour Amber	AMB				

Body Dimensions

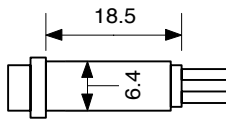

Lens Options

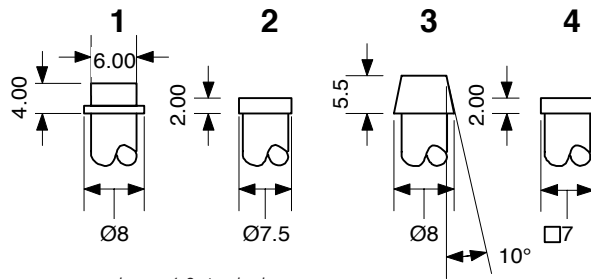

lenses 1-3 standard

## 504 05 Series

- Snap fit body for panel thicknesses 0.5-3.5mm, panel cut-out 13mm diameter
- 6.3mm quick-connect terminals as standard
- Stripped 6mm wire termination 162mm long to order
- Neons 125-240V 0.8-1mA, as standard
- LED and Filament 6-48V 25-40mA, to order
- Polycarbonate lens/body and brushed chrome bezel
- Maximum working temperature 105°C
- Red, green, amber lens colour options as standard
- Other lens colour options to order
- Custom wire lengths and specification to order



TYPE NO.	504	2	XX-XXXX	- T /	XXX
504 Series Indicator	504				
Lens Type	2				
6.3mm quick-connect terminal	03				
Stripped wire 162mm long	05				
LED, white cathode & black anode wires	LED				
Filament 6V 40mA, white wire	640				
Filament 12V 40mA, yellow wire	1240				
Filament 14V 40mA, yellow wire	1440				
Filament 24V 35mA, green wire	24				
Filament 28V 30mA, green wire	28				
Filament 48V 25mA, green wire	48				
Neon 125V 1mA, blue wire	125				
Neon 240V 0.8mA, red wire	240				
Transparent lens	T				
Lens colour Red	RED				
Lens colour Green	GRN				
Lens colour Amber	AMB				

Dimensions

