



# GSM GPS Combo Rugged 'Puck'

- GPS & GSM/CDMA Antenna
- Rugged Screw Fix connector
- Low Profile
- Operates from -30 to +80°C

## GPS

- 1575.42MHz +/- 1MHz
- Active gain: 27dB typ
- Noise Figure 1.5max
- 3metres RG174 Cable
- SMA Male Connector
- Operates from 3—5V

## GSM

- Quad Band Antenna  
800/900/1800/1900MHz
- Active gain: +0dBi
- VSWR <2.0:1
- Omni directional
- SMA Male
- 3m RG174 Connecting Lead



## Applications

- Car GPS Systems
- Hand held GPS Systems

## Description

A compact Antenna for GPS applications where high performance is required from a small size. The antenna includes a Low Noise Amplifier and incorporates is housed in a rugged low profile UV resistant, this antenna is compact and resistant to Vandalism.

## Part Numbers

	Description	Cable Length	Connector
<b>ANT-GSMGPSUKA</b>	Combo GSM & GPS Ant Adhesive mount	3metres	SMA (M)

R F Solutions Ltd.,  
Unit 21, Cliffe Industrial Estate,  
Lewes, E. Sussex. BN8 6JL. England.


Email : [sales@rfsolutions.co.uk](mailto:sales@rfsolutions.co.uk) <http://www.rfsolutions.co.uk>

Tel: +44 (0)1273 898 000 Fax: +44 (0)1273 480 661






# GSM GPS Combo Rugged 'Puck'

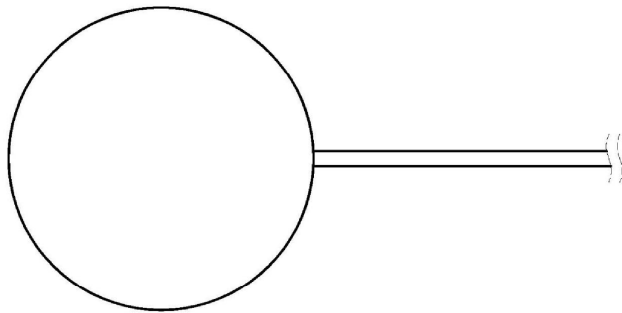

TOP VIEW

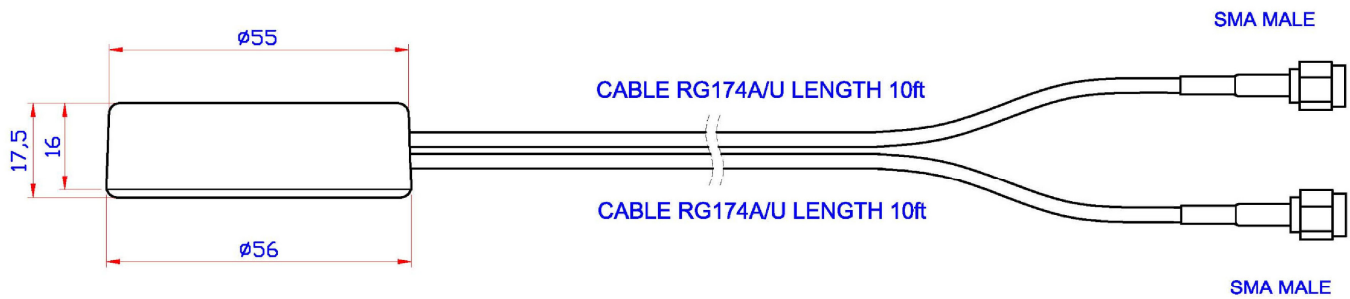

R F Solutions Ltd.,  
Unit 21, Cliffe Industrial Estate,  
Lewes, E. Sussex. BN8 6JL. England.

Email : [sales@rfsolutions.co.uk](mailto:sales@rfsolutions.co.uk) <http://www.rfsolutions.co.uk>

Tel: +44 (0)1273 898 000 Fax: +44 (0)1273 480 661

