

PHILIPS


6996P 1000W GX9.5 230V 1CT



General

PRODUCT DATA	
Order code	184931 25
Full product code	871150018493125
Full product name	6996P 1000W GX9.5 230V 1CT
Order product name	6996P 1000W GX9.5 230V 1CT/10
Packing type	1 Carton
Pieces per pack	1
Packing configuration	10
Packs per outerbox	10
Bar code on pack - EAN1	8711500184931
Bar code on intermediate packing - EAN2	-
Bar code on outerbox - EAN3	8711500184948
Logistic code(s) - 12NC	9238 651 43228
ILCOS code	-
Net weight per piece	0.039 (KG)
Successor order code	-
Philips Code	6996P
Rated Lamp Wattage[W]	1000W
Cap-Base	GX9.5
Voltage[V]	230V
Packing Type	1CT [1 Carton]
Packing Configuration	10
ANSI Code	FWP
LIF Code	T/19 (T/11)
System Description	P3 Technology
Bulb Finish	Clear
Filament Shape	Bi-Plane
Burning Position	any
Main Application	Entertainment
Life to 50% failures[hr]	900
Product Nett Weight[gr]	75
Rapid Acting HBC Fuse[V]	6.3
Lamp Luminous Flux[Lm]	21000
Filament Dimensions (WxH) [mm]	15X13

Dimensions

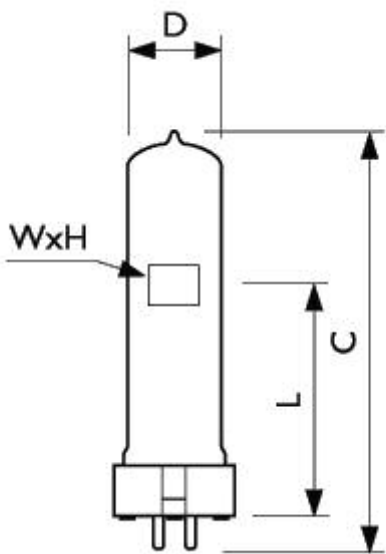

PRODUCT DIMENSIONS	
Characteristic	Value
Overall Length C	109 mm
Diameter D	27 mm
Light Center Length L	55 mm