
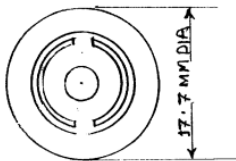


Datasheet

MBC panel lampholder

RS Stock number [589-783](#)

Dimensions: (mm)


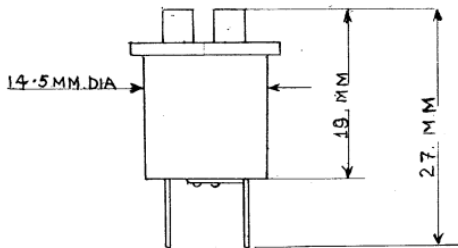


SCALE: 2-1

Specification



- Body: Black Polycarbonate
- Shell: Nickel Plated Brass
- Tags: Brass, Hot Tin Dipped
- Rivets: Brass or Copper, Electro-Tinned
- Eyelet: Nickel Plated Brass
- Internal Washer: SRBP
- Contact: Nickel Plated Brass

P. E. 12. M. E. S. LAMPHOLDER.
(E. 10)

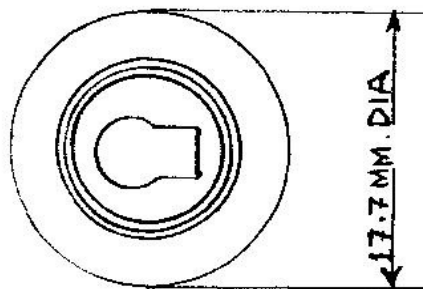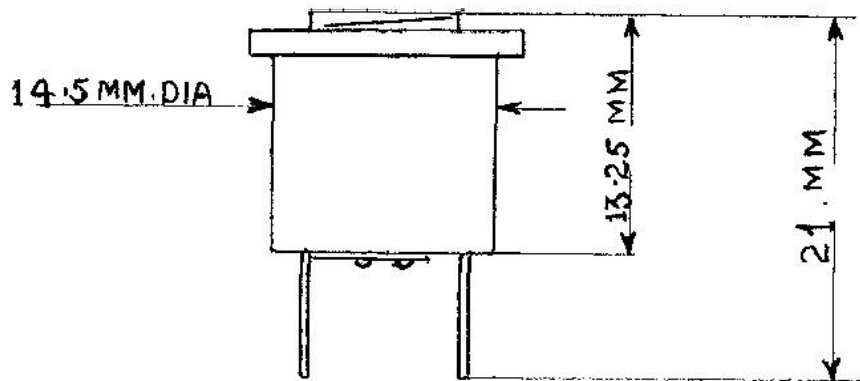

SCALE: 2-1


P.E.12. M.B.C. LAMPHOLDER
(B.A.9.5)

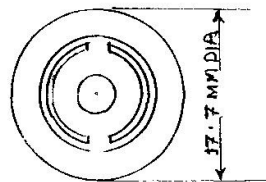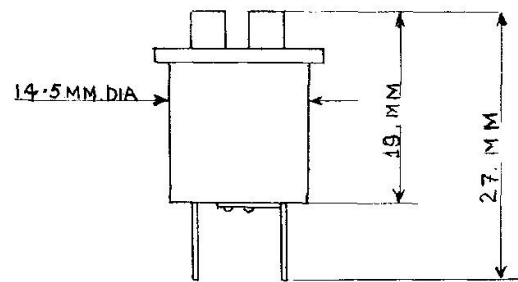

SCALE: 2-1

P.E. 12 M.E.S. AND M.B.C. LAMPHOLDERS

MOULDED BEZEL

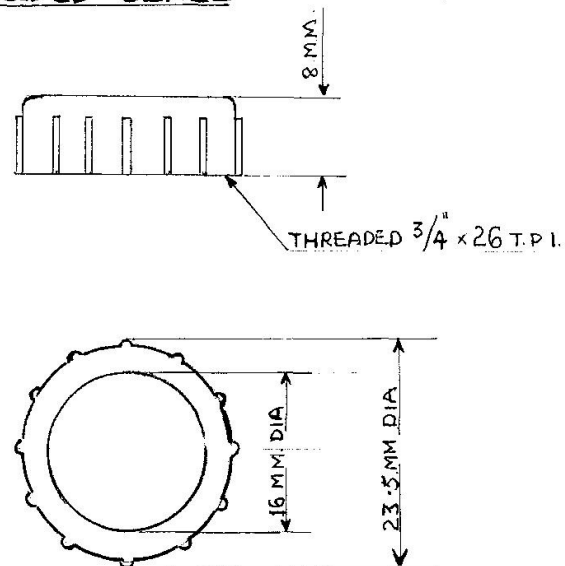

SCALE: 2-1



Materials List.

Parts PE12(MES) & PE12(MBC) subassemblies:

Body - Black polycarbonate.
Shell - nickel plated brass.
Tags - brass, hot tin dipped.
Rivets - brass or copper, electro-tinned.
Eyelet - nickel plated brass.
Internal washer - S.R.B.P..
Contact - nickel plated brass..

Retaining Bezel:

Black Polyamide Type 6.

North Lynn Industrial Estate . King's Lynn
Norfolk . PE30 2HZ

A.V. Shelley B.Sc. D.Phil