

ACCESSORIES 10 (3/8")

3019

CONVERTOR 3/8" TO 1/2"

- Acc. to DIN 3123, ISO 3316
- For hand-operated sockets and accessories with square drive as per DIN 3120, ISO 1174, with ball locking device
- GEDORE vanadium steel 31CrV3, polished, chrome-plated

10
3/8"
12,5
1/2"


Code	No.	□"	□	■"	■	↳mm↳	↻	📦	£
6236010	3019	3/8	10	1/2	12,5	35	53	10	

3020

REDUCER 3/8" TO 1/4"

- Acc. to DIN 3123, ISO 3316
- For hand-operated sockets and accessories with square drive as per DIN 3120, ISO 1174, with ball locking device
- GEDORE vanadium steel 31CrV3, polished, chrome-plated

10
3/8"
6,3
1/4"


Code	No.	□"	□	■"	■	↳mm↳	↻	📦	£
6236280	3020	3/8	10	1/4	6,3	28,5	26	10	

3081

L-HANDLE 3/8"

- Acc. to DIN 3122, ISO 3315
- For hand-operated sockets and accessories with square drive as per DIN 3120, ISO 1174, with ball locking device
- GEDORE vanadium steel 31CrV3, polished, chrome-plated

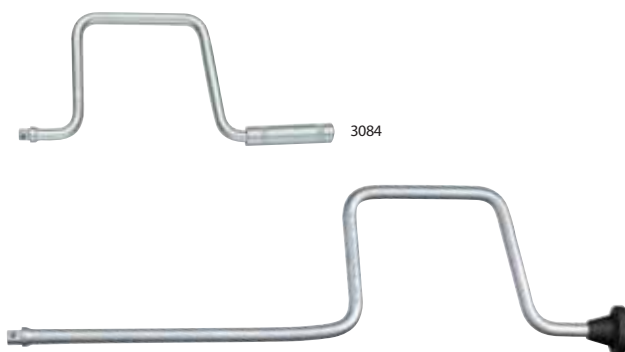
10
3/8"


Code	No.	■"	■	↳mm↳	↻	📦	£
6236360	3081	3/8	10	180	153	10	

3084

SPEED BRACE 3/8"

- Acc. to DIN 3122, ISO 3315
- For hand-operated sockets and accessories with square drive as per DIN 3120, ISO 1174, with ball locking device
- GEDORE vanadium steel 31CrV3, polished, chrome-plated
- No. 3084 L for applications e.g. in the aviation sector

10
3/8"


3084 L

Code	No.	■"	■	↳mm↳	↻	📦	£
6236440	3084	3/8	10	288	423	10	
1965395	3084 L	3/8	10	463	568	1	

3087

SLIDING T BAR 3/8"

- Acc. to DIN 3122, ISO 3315
- For hand-operated sockets and accessories with square drive as per DIN 3120, ISO 1174, with ball locking device
- GEDORE vanadium steel 31CrV3, polished, chrome-plated

10
3/8"


Code	No.	■"	■	↳mm↳	↻	📦	£
6236520	3087	3/8	10	163	164	5	

3087 A

SLIDING T BAR WITH RELEASE 3/8"

- Secured against unintentional removal
- GEDORE vanadium steel 31CrV3, polished, chrome-plated
- Turn handle for easy locking and releasing
- Accidental release when working is prevented because of the asymmetrical release point
- Particularly useful for work in sensitive areas where certainty against loss is a theme
- Examples: Aircraft engine, work in deep machine bodies
- DBGM (German utility patent)

10
3/8"


Code	No.	■"	■	↳mm↳	↻	📦	£
1871633	3087 A	3/8	10	163	135	1	

3090

EXTENSION 3/8"

- Acc. to DIN 3123, ISO 3316
- For hand-operated sockets and accessories with square drive as per DIN 3120, ISO 1174, with ball locking device
- GEDORE vanadium steel 31CrV3, polished, chrome-plated
- * not standardised

10
3/8"


Code	No.	*	■"	■	↳mm↳	↻	📦	£
1476637	3090-2	*	3/8	10	50	63	5	
6236600	3090-3		3/8	10	76	93	5	
6236790	3090-5		3/8	10	125	117	5	
1476645	3090-7	*	3/8	10	180	164	5	
6236870	3090-10		3/8	10	250	222	5	
6238570	3090-12	*	3/8	10	305	287	5	
1476653	3090-20	*	3/8	10	500	524	1	