



■ HALOGEN MEDIUM HM 35W

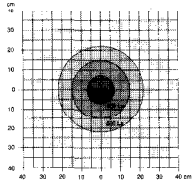

HM 35W

■ HM 35W – FLEX


- Arm length 500 or 700 mm
- 230V/12V with integrated transformer
- 12 or 24V direct connection
- With jointed lamp head or without jointed lamp head
- With dimmer or without dimmer

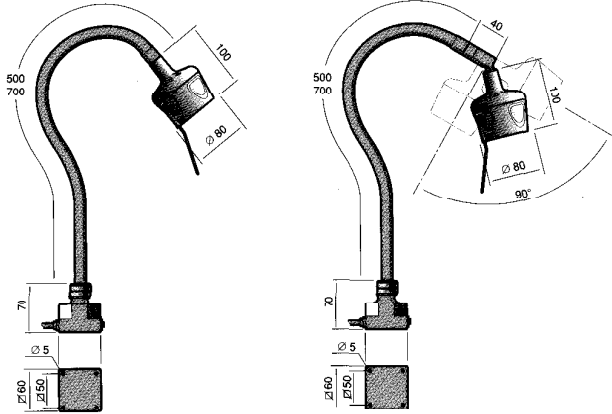

RS# 366-0469 -->

■ HM 35W – SPOT


- Single or double-jointed head
- 230V/12V with integrated transformer
- 12 or 24V direct connection

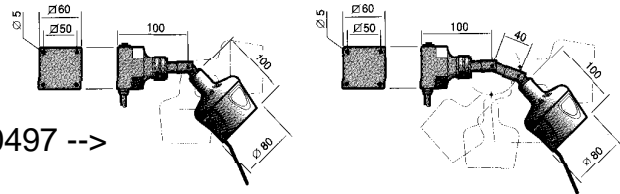


RS# 366-0497 -->

■ HM 35W – AAS

- Two-section 1000 mm or three-section 1250 mm rigid arm
- 12 or 24V

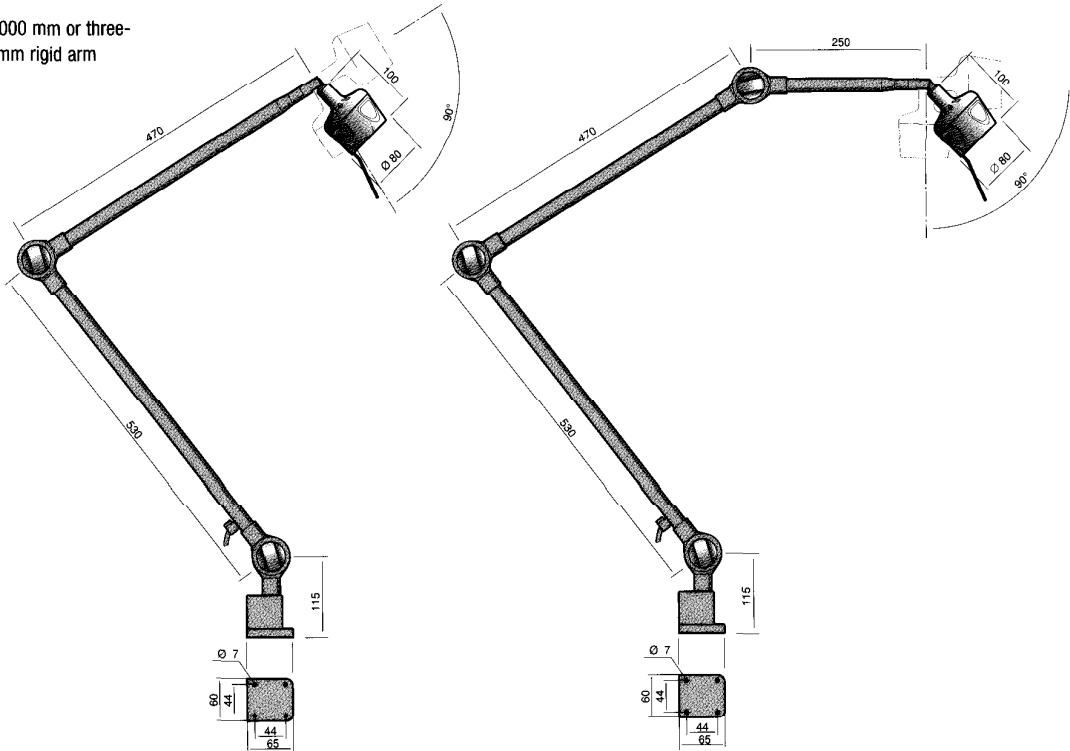


■ HALOGEN SPOT HS 20W

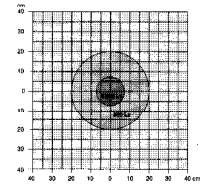

HS 20W


■ HS 20W – FLEX

- Arm length 250, 500 or 700 mm
- 230V/12V – transformer base
- 12 or 24V – sub base
- With jointed lamp head or without jointed lamp head
- With dimmer or without dimmer
- Safety class IP20 or IP65
- Quick connector with 350–1500 mm curly cable to the head is optional

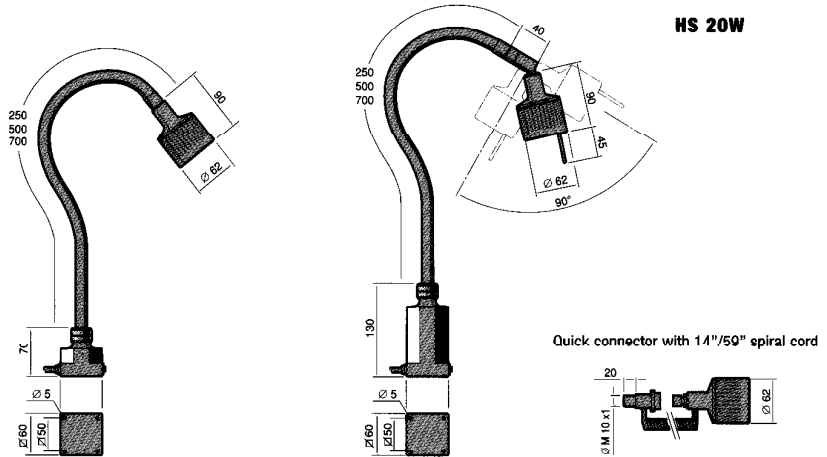

■ HS 20W – SPOT

- Single or double-jointed lamp head
- 230V/12V – transformer base
- 12 or 24V – sub base

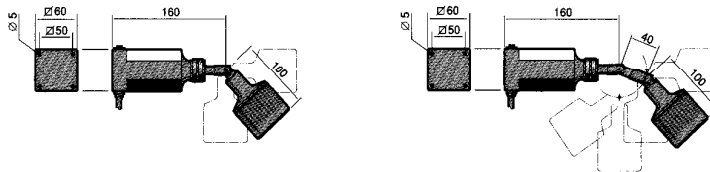

■ HS 20W – AAS

- Two-section 1000 mm or three-section 1250 mm rigid arm
- 12 or 24V

