

Product Information



3470UOO125P30-13

EAN 4031582304664


Swivel castor, housing made of pressed steel, bright zinc plated, blue passivated, double ball bearing swivel head, wheel axle with nut, bolt hole.

Wheel centre made of Polyamide, plain bearing

Technical Data

Wheel diameter	125 mm
Width of Tread	40 mm
Centre hole	13 mm
Offset	40 mm
Swivel Interference	205 mm
Overall height	155 mm
Temperature	- 20 / + 60 °C
Standard	EN 12532
Weight	0.928 kg
Swivel Radius	102.5 mm
Hardness of tread	D 75 Shore
Load capacity	150 kg
Load capacity (static)	300 kg

Roll performance	+	+	+	+	+
Movement noise	+	+	+	+	+
Attrition	+	+	+	+	+
Corrosion resistance	+	+	+	+	+

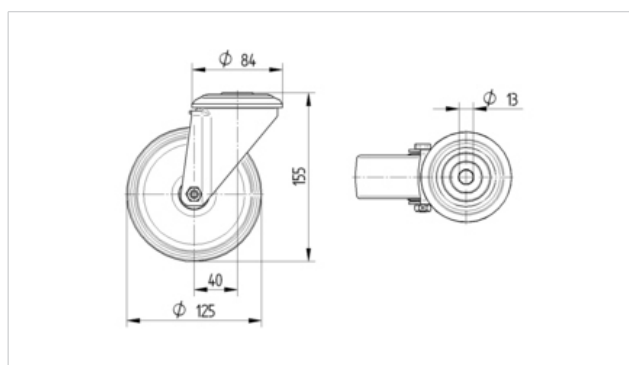

3470UOO125P30-13

EAN 4031582304664

