 
 








<p>2 x 0.5 ... 4 mm² ① 400 V/6 kV/3 I_N 25 A</p> <p> 9 mm / 0.35 in.</p> <p>② Approvals</p>	<p>2 x 20 ... 12 AWG</p>	<p>2 x 0.5 ... 4 mm² ① 400 V/6 kV/3 I_N 25 A</p> <p> 9 mm / 0.35 in.</p> <p>② Approvals</p>	<p>2 x 20 ... 12 AWG</p>	<p>Snap-in frame - for 5-pole sockets and plugs (see pages 133 and 135)</p>
---	--------------------------	---	--------------------------	---



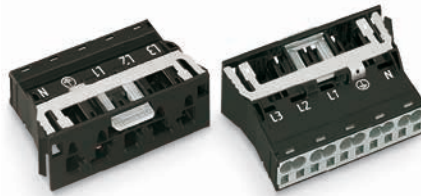

Color	Item No.	Pack. Unit	Color	Item No.	Pack. Unit	Color	Item No.	Pack. Unit
Plug			Plug with direct ground contact ③			Snap-in frame, 5-pole, for 0.5 ... 2 mm plate thickness		
● black	770-715	50	● black	770-715/007-000	50	black	770-321	100
○ white	770-735	50	○ white	770-735/007-000	50	white	770-341	100
● blue	770-2115	50	● blue	770-2115/007-000	50	Snap-in frame, 5-pole, for 1 ... 3 mm plate thickness, suitable for coding A / B / I / P / Q		
● red	770-2315	50	For "Clean Earth" applications (loading up to 32A):			black	770-320	100
For "Clean Earth" applications (loading up to 32A):			For "Clean Earth" applications (loading up to 32A):			white	770-340	100
● green	770-2335	50	● green	770-2335/007-000	50			

Item-Specific Accessories

<p>Lockout cap, for plug, separable, 5-pole</p> <p> yellow 770-360 100</p>	<p>Lockout cap, for plug, separable, 5-pole</p> <p> yellow 770-360 100</p>	<p>Locking lever, tool operated</p> <p> gray 770-140 100 (4x25)</p>
<p>Coding pin, for plug (A and B coding)</p> <p> gray 770-401 100</p>	<p>Coding pin, for plug (A and B coding)</p> <p> gray 770-401 100</p>	

Accessories, 770 Series

<p>Lockout cap, for cutout, 5-pole</p> <p> black 770-645 100 white 770-695 100</p>	<p>Lockout cap, for cutout, 5-pole</p> <p> black 770-645 100 white 770-695 100</p>
--	--

Dimensions

