

Professionally approved products.


Datasheet

4 Way Male Cable Mount Loudspeaker Connector, 20A

RS Stock 460-250



Dimensions: (mm)

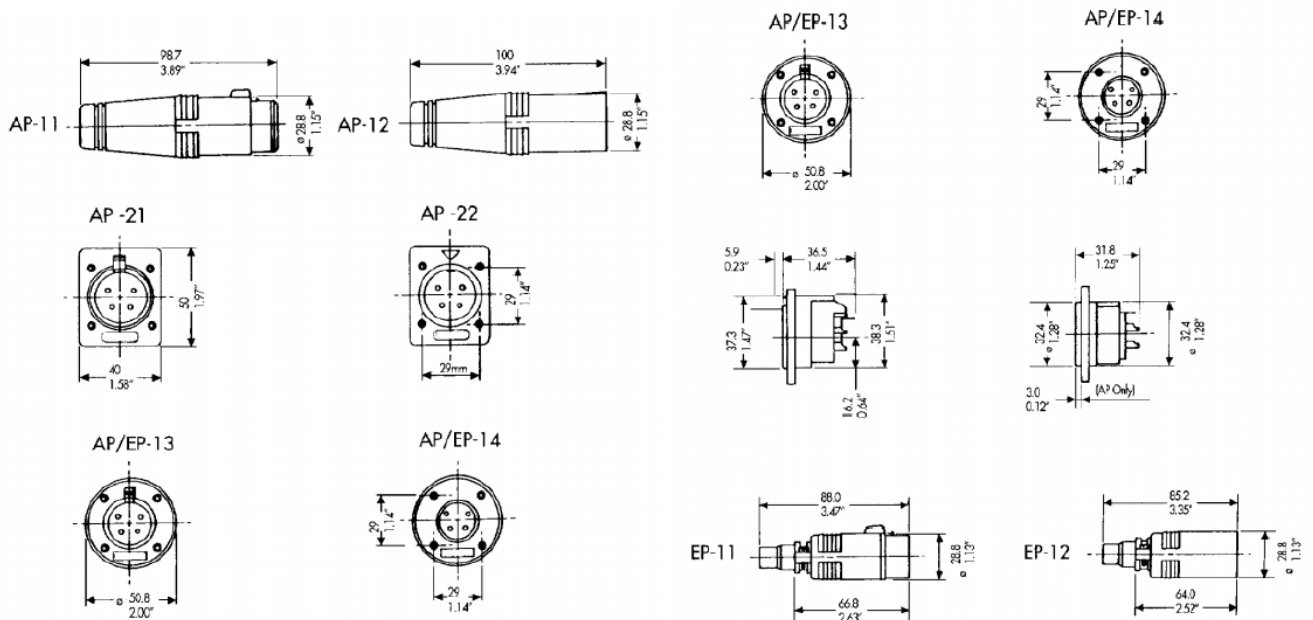

Professionally approved products.

Datasheet

Specification

Cable OD	11mm to 17mm (0.43" to 0.67")
Cable Retention Force	Typically 22 to 44kg (50 to 10lb)
Retention Method	2 opposing plastic screws on 11 & 12 only
Shell	Modified PPE Resin Black
Insulators	UL94-O PBT Resin
Contacts	Precision machined Brass / Bright Tin / Solder Cup
Cable Bushing	Silicon Rubber
Operating Temp	-25°C to +75°C
Contact Resistance	$\leq 3\text{m } \Omega$
Insulation Resistance	$\geq 10^3 \text{ meg } \Omega$
Connector Insertion	$\geq 10 / \leq 30$