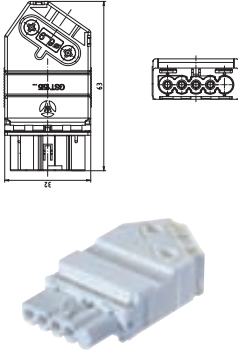
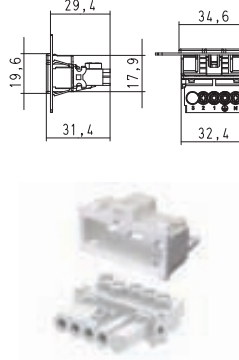
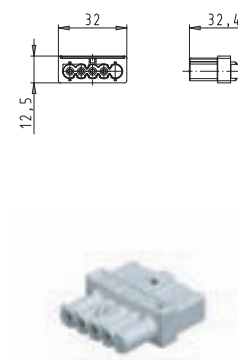
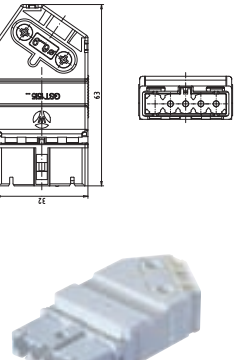
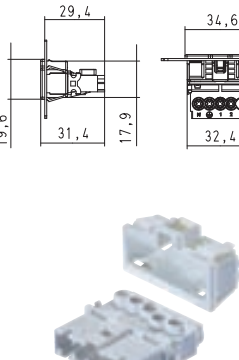


GST 15i 4 pole 250V/16A/6A


			Connectors		Appliance couplers		Intermediate coupling	
			with strain relief for wire diameters 6.0 – 8.5mm (H05VV-F, NYM) ²⁾ Wire cross section: 0.75 – 1.5mm ² solid and fine-stranded without ferrule, with locking device		Material thickness: 0.5 – 1.5 mm latches into the housing cut-out ¹⁾ , 1 connection point per pole screw connection , solid and fine-stranded conductors 0.5 – 1.5mm ² with locking device		for direct routing e.g. from luminaire to luminaire 1 input , Male part 4 pole 1 output , Female part 4 pole	
			Sheath strip length: 21 mm Insulation strip length: 8 mm		Insulation strip length: 8 mm			
Application	Coding	Color	Part No.	Std. Pack	Part No.	Std. Pack	Part No.	Std. Pack
Female connector								
Mains with ground	Code 1 	white	91.941.3053.0		91.941.9053.0		91.040.5953.0	
		Type						
								
Application	Coding	Color	Part No.	Std. Pack	Part No.	Std. Pack		
Male connector								
Mains with ground	Code 1 	white	91.942.3053.0		91.942.9053.0			
		Type						
			²⁾ Other cables available on request ³⁾ Coding for low-voltage applications 50V, 16A		¹⁾ Housing material, paint and deburring may influence the tight fit inside the housing. Detailed installation instructions available on request.			

24



GST 15i4

4 pole

GST 15i4

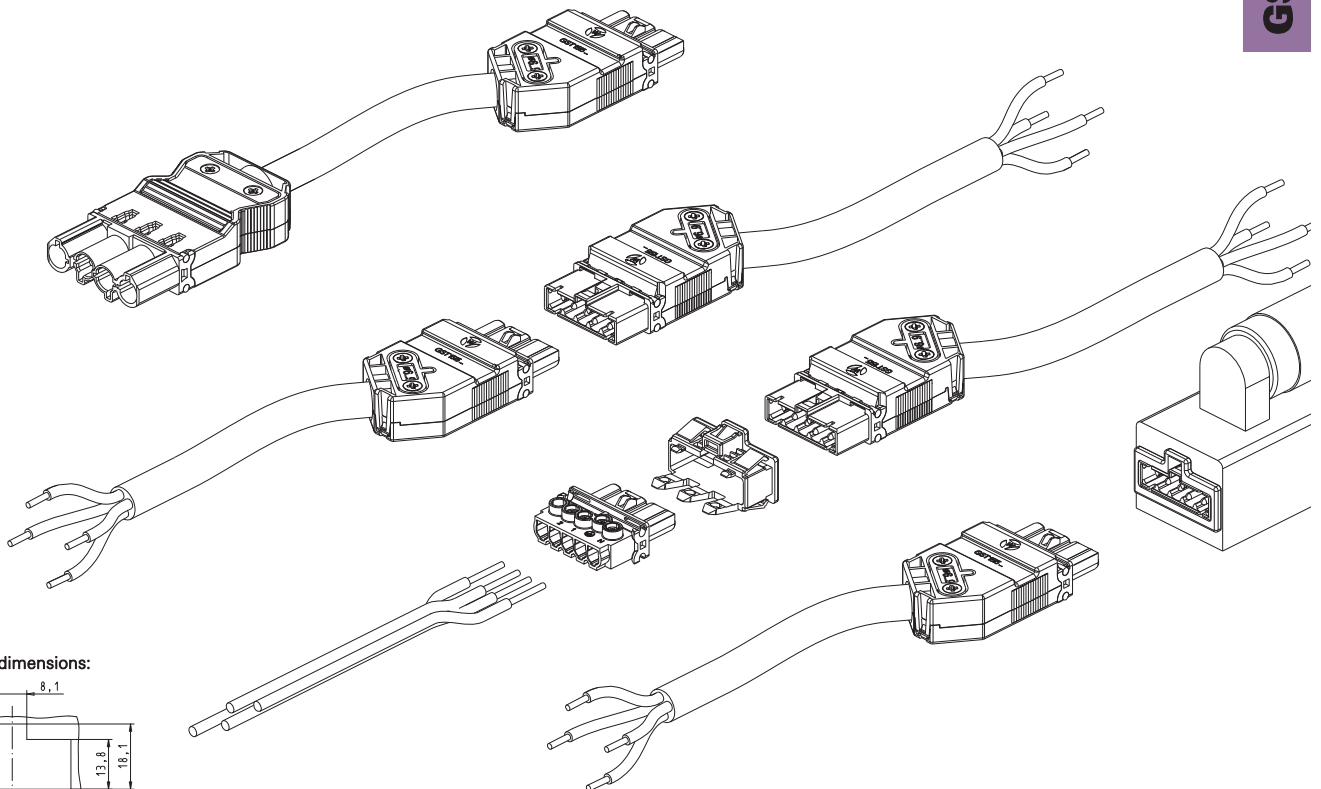

Cut-out dimensions:

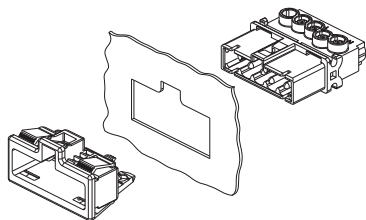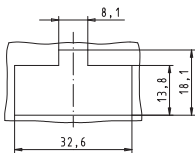

Cut-out dimensions:

