





 
DESCRIPTION:
PART NUMBER:
APPLICATION:
DURABILITY:
IMPEDANCE:
WORKING TEMP RANGE:
MATERIAL:

USB EXT, VERSION 2.0, A-MALE TO A-FEMALE, 6 FT
30-3008-6
USB 2.0 CABLE
1500 CYCLES MIN
N/A
-25°C TO +80°C
USB AM & AF
CABLE

GOLD FLASH ON CONTACT, PVC MOLDED GRAY
USB 2.0 CABLE, UL STYLE, 1P TWISTED 28AWG
AND 2C 24AWG, AMA BRAID, JACKET GRAY

RoHS COMPLIANCE: YES
TECHNICAL DETAIL: N/A

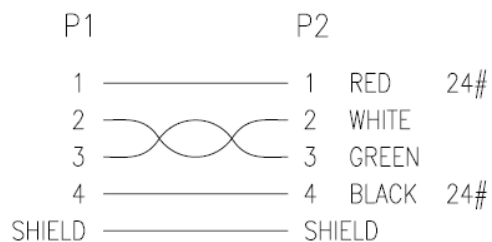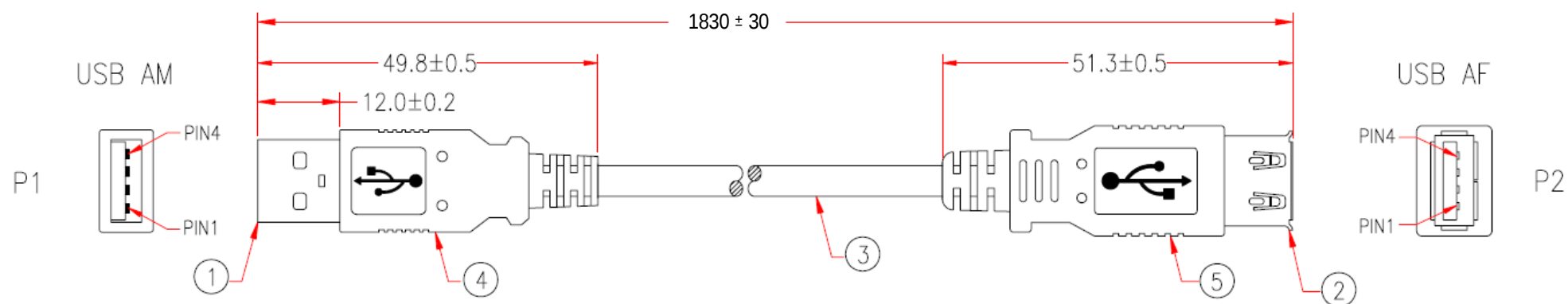

 This PROPRIETARY document is property of Cinch Connectivity Solutions. It is confidential in nature, non-transferable, and issued with the clear understanding that it is not to be copied or used without permission and is returnable upon demand. INTERPRET DRAWING IN ACCORDANCE WITH ASME Y14.5-2009.	 RoHS2 ☒ 2011/65/EU UNLESS OTHERWISE SPECIFIED UNITS: METRIC .X ±.2 .XX ±.07 ANGLES ±2°	AIM-Cambridge Title: USB EXT, VERSION 2.0, A-MALE TO A-FEMALE, 6 FT Model No. 30-3008-6		
		Size	DO NOT SCALE DRAWING	Date: 2015/12/4
		A		Sheet 1 of 1