
 


B4 Series | Illuminated double-pole switch 16A quick connection 6.3 black body

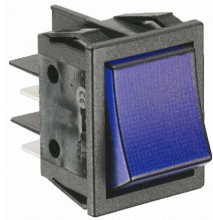

sample image

PRODUCT CODE: B418C1F000000



Body colour





Actuator colour

Rating

16 (6) A / 250 VAC
10 (4) A / 250 VAC - 5E4
T120/55 °C

20 A / 125 VAC
16 A / 250 VAC
1/3 HP - 125 VAC
3/4 HP - 250VAC
T105 °C

Approvals

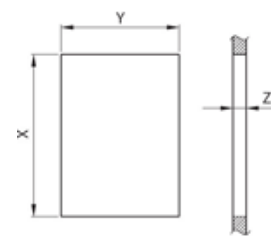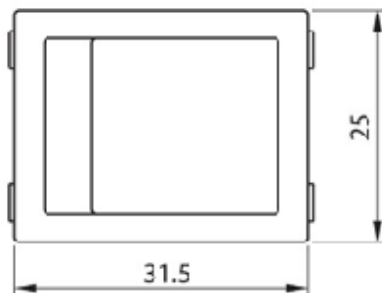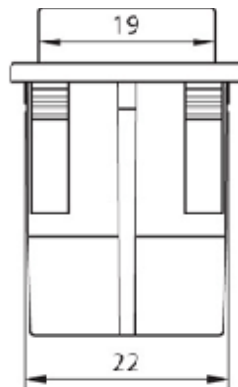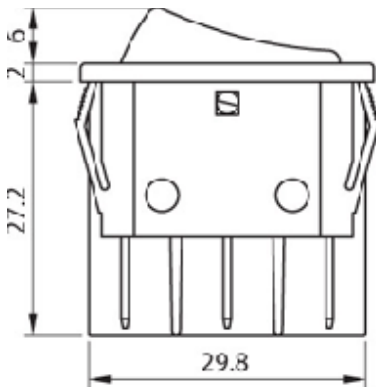

Cut out (mm)

Z	Y	X
0.75 ... 1.25	22.0 ^{+0.2} ₀	30.0 ⁰ _{-0.1}
1.25 ... 2.0	22.0 ^{+0.2} ₀	30.2 ⁰ _{-0.1}
2.0 ... 3.0	22.0 ^{+0.2} ₀	30.6 ⁰ _{-0.2}
3.0 ... 4.0	22.0 ^{+0.2} ₀	30.8 ⁰ _{-0.2}